

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0528072210

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

1.00mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Non-ZIF, Top Contact Style Receptacle, 22 Circuits

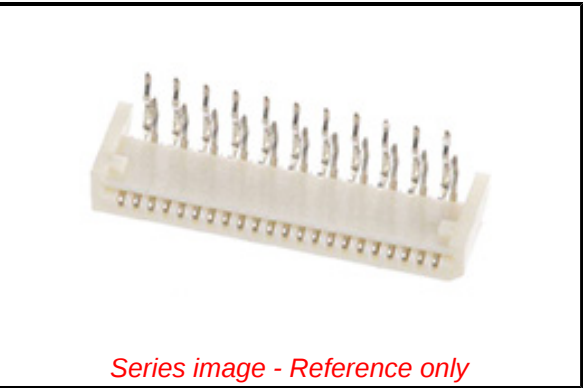

Series image - Reference only

Documents:	
3D Model (PDF)	Product Specification PS-52807-003-001 (PDF)
3D Model	Packaging Specification SPK-52807-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	FFC/FPC Connectors
Series	52807
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
Taxonomy	FFC / FPC Connectors
UPC	800754313971
Physical	
Actuator Type	Non-ZIF
Circuits (Loaded)	22
Color - Resin	Natural
Contact Position	Top
Flammability	94V-0
Mated Height	3.60mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	674.101/mg
Number of Rows	1
Orientation	Right Angle
PC Tail Length	3.20mm
PCB Mounting	Through Hole - Kinked Pin
PCB Retention	None
Packaging Type	Tray
Pitch - Mating Interface	1.00mm
Pitch - Termination Interface	1.00mm
Plating min - Mating	0.914µm
Plating min - Termination	0.914µm
Polarized to PCB	Yes
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-20° to +80°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.2A, 0.4A, 0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	SPK-52807-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[52807 Series](#)

This document was generated on 01/18/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION