

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022552083](#)
Status: **Active**
Overview: [SL Modular Connectors](#)
Description: 2.54mm Pitch SL Crimp Housing, Dual Row, Version C, Back Ribs, 8 Circuits, Black

Documents:

Drawing (PDF)	Product Specification PS-70400-001 (PDF)
3D Model (PDF)	Packaging Specification PK-70450-100-001 (PDF)
3D Model	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version C
Overview	SL Modular Connectors
Product Name	SL
Taxonomy	Connector Housings
UPC	800754396189

Physical

Breakaway	No
Circuits (maximum)	8
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	0.712/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40° to +105°C

Solder Process Data


Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Engineering Number	704500102
--------------------	-----------

Reference - Drawing Numbers

Packaging Specification	PK-70450-100-001
Product Specification	PS-70058-001, PS-70400-001
Sales Drawing	SD-70450-0100-0125-001
Test Summary	TS-70058-001-001

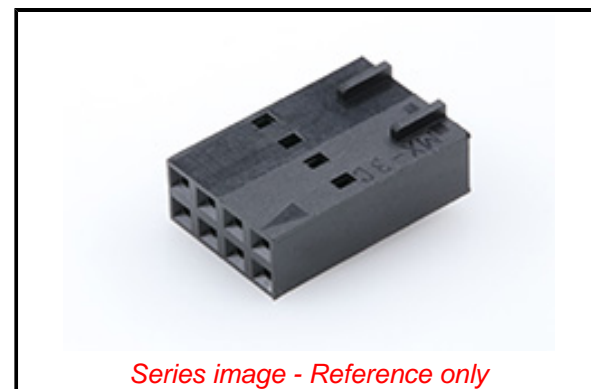

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[70450 Series](#)

Mates With

C-Grid Right-Angle Header [70229](#) , [70247](#) .

C-Grid Vertical Breakaway Header [70280](#) .

C-Grid Vertical Header [70246](#)

Use With

[70058](#) , [71851](#)