


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0441331600
Status: Active
Overview: Micro-Fit Connector System
Description: Micro-Fit BMI Receptacle Housing, Dual Row, Panel Mount, 16 Circuits, Polyester, UL 94V-0

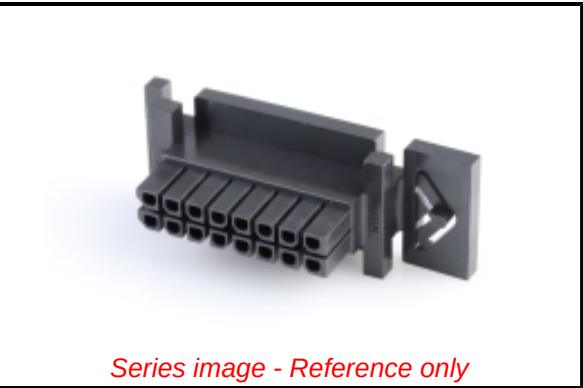

Series image - Reference only

Documents:

- | | |
|--|--|
| 3D Model (PDF) | Test Summary TS-43045-001-001 (PDF) |
| 3D Model | Test Summary TS-43045-002-001 (PDF) |
| Drawing (PDF) | Test Summary TS-46235-001-001 (PDF) |
| Product Specification PS-44300-001-001 (PDF) | Datasheet (PDF) |
| Application Specification 443000001-AS-000 (PDF) | RoHS Certificate of Compliance (PDF) |
| Packaging Specification PK-44133-002-001 (PDF) | |

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	44133
Application	Power, Wire-to-Board, Wire-to-Wire
Overview	Micro-Fit Connector System
Product Name	Micro-Fit BMI
Taxonomy	Connector Housings
UPC	800753132948

Physical

Circuits (maximum)	16
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	No
Material - Resin	Polyester
Net Weight	3.335/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	3.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Application Specification	443000001-AS-000
Packaging Specification	PK-44133-002-001
Product Specification	PS-44300-001-001
Sales Drawing	SD-44133-001-001
Test Summary	TS-43045-001-001, TS-43045-002-001, TS-46235-001-001

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

44133 Series

Mates With

443001600 Panel Mount Plug, 44432 Micro-Fit 3.0 BMI Vertical 16 Circuit Headers, 44428 Micro-Fit 3.0 BMI Right Angle 16 Circuit Headers, 45280 Micro-Fit 3.0 BMI CPI Vertical 16 Circuit Headers

Use With

Micro-Fit 3.0 Female Crimp Terminals 43030 , 45773
Micro-Fit RMF Female Crimp Terminals 46235
Micro-Fit 3.0 Pre-Crimped Leads 797580002 , 797580004 , 797580010 , 797580012 , 214760 , 214761

This document was generated on 10/20/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION