

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0901230106

Status:


Active

Overview:

C-Grid III Interconnects

Description:

2.54mm Pitch C-Grid III Modular Crimp Housing Single Row, 2 Polarizing Buttons, 6 Circuits, Black

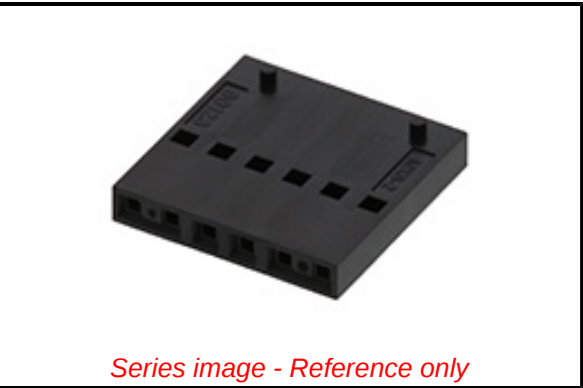

Documents:

3D Model (PDF)

Application Specification 901190001-AS-000 (PDF)

Drawing (PDF)

Packaging Specification PK-90123-0001-001 (PDF)

3D Model

RoHS Certificate of Compliance (PDF)

Product Specification PS-99020-0001-001 (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	90123
Application	Signal, Wire-to-Board
Comments	2 Polarizing Buttons
Overview	C-Grid III Interconnects
Product Name	C-Grid III
Taxonomy	Connector Housings
UPC	800753706880
Physical	
Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-1
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	PPO
Net Weight	0.344/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-55° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	901190001-AS-000
Packaging Specification	PK-90123-0001-001
Product Specification	PS-99020-0001-001
Sales Drawing	SD-90123-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Low-Halogen

Status

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

90123 Series

Mates With

C-Grid III Vertical Header 90120 , 90136 . C-Grid III Right-Angle Header 90121

Use With

C-Grid III Crimp Terminal 90119
 C-Grid III Pre-Crimped Lead 797582022 , 797582023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION