

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0559321530

Status:


Active

Overview:

MicroClasp Wire-to-Board System

Description:

2.00mm Pitch MicroClasp Wire-to-Board Header, Single Row, Vertical, 15 Circuits, without PCB Locator

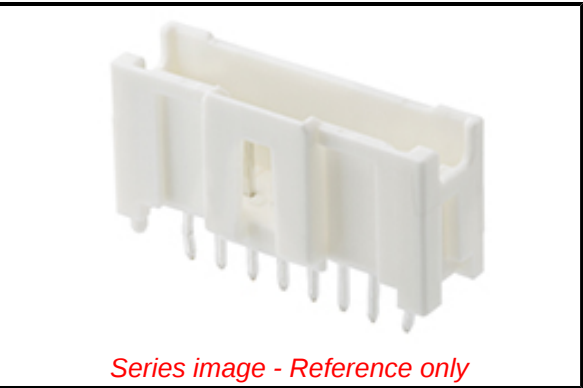

Documents:	
3D Model	Product Specification PS-51382-004-001 (PDF)
3D Model (PDF)	Application Specification 561340000-AS-000 (PDF)
Drawing (PDF)	Packaging Specification SPK-55932-001-001 (PDF)
Product Specification 513820000-PS-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E29179
General		
Product Family		PCB Headers
Series		55932
Application		Signal, Wire-to-Board
Component Type		PCB Header
Overview		MicroClasp Wire-to-Board System
Product Name		MicroClasp
Taxonomy		PCB Headers and Receptacles
UPC		800756632513
Physical		
Breakaway		No
Circuits (Loaded)		15
Circuits (maximum)		15
Color - Resin		Natural
Durability (mating cycles max)		30
First Mate / Last Break		No
Glow-Wire Capable		No
Guide to Mating Part		No
Keying to Mating Part		None
Lock to Mating Part		Yes
Material - Plating Mating		Tin
Material - Plating Termination		Tin
Material - Resin		Polyester
Net Weight		1331.000/mg
Number of Rows		1
Orientation		Vertical
PC Tail Length		3.20mm
PCB Locator		No
PCB Retention		Yes
PCB Thickness - Recommended		1.60mm
Packaging Type		Tray
Pitch - Mating Interface		2.00mm
Shrouded		Fully
Stackable		No
Surface Mount Compatible (SMC)		No
Temperature Range - Operating		-40° to +105°C
Termination Interface: Style		Through Hole
Electrical		
Current - Maximum per Contact		3.0A
Voltage - Maximum		250V AC (RMS)/DC

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

55932 Series

Mates With

MicroClasp Receptacle Housing [51382](#)

Material Info

Reference - Drawing Numbers

Application Specification	561340000-AS-000
Packaging Specification	SPK-55932-001-001
Product Specification	513820000-PS-001, PS-51382-004-001
Sales Drawing	SD-55932-006-001, SD-55932-007-001

This document was generated on 02/07/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION