

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0510671100

Status:


Active

Overview:

Mighty-SPOX Connector System

Description:

Mighty-SPOX Wire-to-Wire and Wire-to-Board Housing, 3.50mm Pitch, Positive Lock, 11 Circuits, Natural

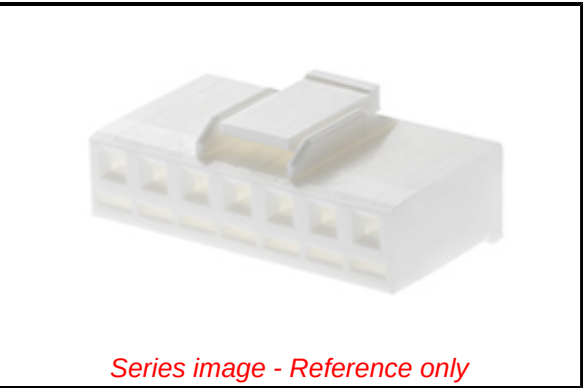

Series image - Reference only

Documents:

|                                                              |                                                                 |
|--------------------------------------------------------------|-----------------------------------------------------------------|
| <a href="#">3D Model</a>                                     | <a href="#">Product Specification PS-51067-008-001 (PDF)</a>    |
| <a href="#">3D Model (PDF)</a>                               | <a href="#">Product Specification PS-51067-016-001 (PDF)</a>    |
| <a href="#">Drawing (PDF)</a>                                | <a href="#">Product Specification PS-51067-017-001 (PDF)</a>    |
| <a href="#">Product Specification PS-51067-001-001 (PDF)</a> | <a href="#">Product Specification PS-51067-018-001 (PDF)</a>    |
| <a href="#">Product Specification PS-51067-002-001 (PDF)</a> | <a href="#">Product Specification PS-51067-019-001 (PDF)</a>    |
| <a href="#">Product Specification PS-51067-003-001 (PDF)</a> | <a href="#">Product Specification PS-51067-022-001 (PDF)</a>    |
| <a href="#">Product Specification PS-51067-004-001 (PDF)</a> | <a href="#">Packaging Specification SPK-51067-001-001 (PDF)</a> |
| <a href="#">Product Specification PS-51067-005-001 (PDF)</a> | <a href="#">Packaging Specification SPK-51067-001-002 (PDF)</a> |
| <a href="#">Product Specification PS-51067-006-001 (PDF)</a> | <a href="#">RoHS Certificate of Compliance (PDF)</a>            |
| <a href="#">Product Specification PS-51067-007-001 (PDF)</a> |                                                                 |

Agency Certification

|     |         |
|-----|---------|
| CSA | LR19980 |
| UL  | E29179  |

General

|                |                                    |
|----------------|------------------------------------|
| Product Family | Crimp Housings                     |
| Series         | 51067                              |
| Application    | Power, Wire-to-Board, Wire-to-Wire |
| Overview       | Mighty-SPOX Connector System       |
| Product Name   | Mighty-SPOX                        |
| Taxonomy       | Connector Housings                 |
| UPC            | 800754363600                       |

Physical

|                               |                |
|-------------------------------|----------------|
| Circuits (maximum)            | 11             |
| Color - Resin                 | Natural        |
| Flammability                  | 94V-0          |
| Gender                        | Receptacle     |
| Glow-Wire Capable             | No             |
| Material - Resin              | Polyester      |
| Net Weight                    | 2124.200/mg    |
| Number of Rows                | 1              |
| Packaging Type                | Bag            |
| Panel Mount                   | No             |
| Pitch - Mating Interface      | 3.50mm         |
| Stackable                     | No             |
| Temperature Range - Operating | -40° to +105°C |

Material Info

Reference - Drawing Numbers

|                         |                                                                                                                                                                                                                                          |
|-------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Packaging Specification | SPK-51067-001-001, SPK-51067-001-002                                                                                                                                                                                                     |
| Product Specification   | PS-51067-001-001, PS-51067-002-001, PS-51067-003-001, PS-51067-004-001, PS-51067-005-001, PS-51067-006-001, PS-51067-007-001, PS-51067-008-001, PS-51067-016-001, PS-51067-017-001, PS-51067-018-001, PS-51067-019-001, PS-51067-022-001 |
| Sales Drawing           | SD-51067-XX00-001                                                                                                                                                                                                                        |

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -  
D(2022)4187-DC (10  
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

|                 |               |
|-----------------|---------------|
| China ROHS      | Green Image   |
| ELV             | Not Relevant  |
| RoHS Phthalates | Not Contained |

Search Parts in this Series

51067 Series

Mates With

51114 , 53258 , 53259 , 53265 , 53266

Use With

50217 Crimp Terminals

This document was generated on 10/19/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**