

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5056060800

Status:


Active

Overview:

CP Wire-to-Board and Wire-to-Wire Connector Systems

Description:

CP-3.3 Plug Housing, 3.30mm Pitch, Dual Row, Polarized, Positive Inertia Lock, 8 Circuits, Natural

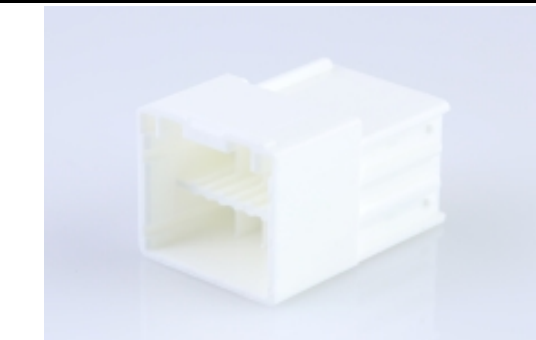

Series image - Reference only

Documents:	
3D Model	Application Specification 5056050000-A01 (PDF)
Drawing (PDF)	Packaging Specification 5056069200-200 (PDF)
3D Model (PDF)	Datasheet (PDF)
Product Specification 5056050000-000 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification 5056050000-A00 (PDF)	

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	505606
Application	Signal, Wire-to-Wire
Overview	CP Wire-to-Board and Wire-to-Wire Connector Systems
Product Name	CP-3.3
Taxonomy	Connector Housings
UPC	889056804462
Physical	
Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	3349.000/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.30mm
Pitch - Termination Interface	3.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	5056050000-A00, 5056050000-A01
Packaging Specification	5056069200-200
Product Specification	5056050000-000
Sales Drawing	5056060000-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

505606 Series

Mates With

Receptacle Housing 5056050800

Use With

Terminal Retainer 504695 . Plug Crimp Terminal 50398 , 505608