

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2122092060

Status:


Active

Overview:

CP Wire-to-Board and Wire-to-Wire Connector Systems

Description:

CP-3.3 Receptacle Housing, 3.30mm Pitch, Dual Row, Positive Lock, Glow-Wire Capable, 6 Circuits, Natural

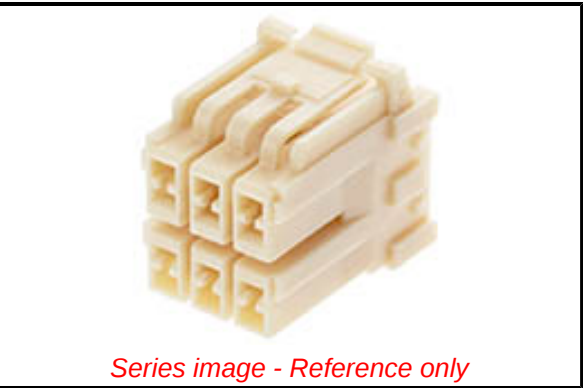

Series image - Reference only

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification 2122090000-PS-000 (PDF)

Packaging Specification 2122099200-SPK-200 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E29179
General		
Product Family		Crimp Housings
Series		212209
Application		Power, Wire-to-Board
Overview		CP Wire-to-Board and Wire-to-Wire Connector Systems
Product Name		CP-3.3
Taxonomy		Connector Housings
UPC		193264099658
Physical		
Circuits (maximum)		6
Color - Resin		Natural
Flammability		94V-0
Gender		Receptacle
Glow-Wire Capable		Yes
Keying to Mating Part		Yes
Lock to Mating Part		Yes
Material - Resin		Polyamide
Net Weight		1447.580/mg
Number of Rows		2
Packaging Type		Bag
Panel Mount		No
Pitch - Mating Interface		3.30mm
Pitch - Termination Interface		3.30mm
Polarized to Mating Part		Yes
Temperature Range - Operating		-40° to +105°C
Material Info		
Reference - Drawing Numbers		
Packaging Specification		2122099200-SPK-200
Product Specification		2122090000-PS-000
Sales Drawing		2122090000-SD-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

212209 Series

Mates With

CP-3.3 Header 212210

Use With

CP-3.3 Retainer 2122132030 . CP-3.3 Crimp Terminals 50397 , 5056070001 , 5056070101

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION