

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0510670800

Status:


Active

Overview:

Mighty-SPOX Connector System

Description:

Mighty-SPOX Wire-to-Wire and Wire-to-Board Housing, 3.50mm Pitch, Positive Lock, 8 Circuits, Natural

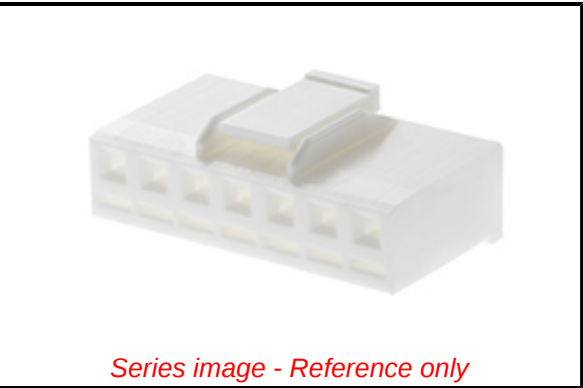

Series image - Reference only

Documents:

- 3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-51067-002-001 (PDF)

Product Specification PS-51067-003-001 (PDF)

Product Specification PS-51067-004-001 (PDF)

Product Specification PS-51067-005-001 (PDF)

Product Specification PS-51067-006-001 (PDF)

Product Specification PS-51067-007-001 (PDF)

Product Specification PS-51067-008-001 (PDF)

Product Specification PS-51067-016-001 (PDF)
- Product Specification PS-51067-017-001 (PDF)

Product Specification PS-51067-018-001 (PDF)

Product Specification PS-51067-019-001 (PDF)

Product Specification PS-51067-020-001 (PDF)

Product Specification PS-51067-021-001 (PDF)

Product Specification PS-51067-022-001 (PDF)

Product Specification PS-51067-023-001 (PDF)

Packaging Specification SPK-51067-001-001 (PDF)

Packaging Specification SPK-51067-001-002 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

Crimp Housings

Series

51067

Application

Power, Wire-to-Board, Wire-to-Wire

Overview

Mighty-SPOX Connector System

Product Name

Mighty-SPOX

Taxonomy

Connector Housings

UPC

800753574427

Physical

Circuits (maximum)

8

Color - Resin

Natural

Flammability

94V-0

Gender

Receptacle

Glow-Wire Capable

No

Material - Resin

Polyester

Net Weight

1598.900/mg

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

3.50mm

Stackable

No

Temperature Range - Operating

-40° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification

SPK-51067-001-001, SPK-51067-001-002

Product Specification

PS-51067-002-001, PS-51067-003-001, PS-51067-004-001, PS-51067-005-001, PS-51067-006-001, PS-51067-007-001, PS-51067-008-001, PS-51067-016-001, PS-51067-017-001, PS-51067-018-001, PS-51067-019-001, PS-51067-020-001,

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

51067 Series

Mates With

51114 , 53258 , 53259 , 53265 , 53266

Use With

50217 Crimp Terminals

This document was generated on 10/20/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION