

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0917780030](#)
Status: **Active**
Overview: RAST Connector System
Description: 5.00mm Appli-Mate RAST 5 IDT Housing, Indirect, Female, 10 Amp, 2 Circuit, Fully Coded

Documents:

[Drawing \(PDF\)](#) [Packaging Specification PK-90833-001-001 \(PDF\)](#)
[Product Specification PS-99020-0037-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family IDT and Solder Connectors
 Series [91778](#)
 Crimp Quality Equipment Yes
 Overview [RAST Connector System](#)
 Product Name RAST 5
 Taxonomy Connector Housings
 UPC 883906937829
 Use With RAST Standard Interface

Physical


Circuits (Loaded) 2
 Circuits (maximum) 2
 Color - Resin Natural
 Durability (mating cycles max) 10
 Flammability 94V-2
 Gender Female
 Glow-Wire Capable Yes
 Lock to Mating Part Yes
 Material - Metal Phosphor Bronze
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Material - Resin Nylon
 Net Weight 2.594/g
 Number of Rows 1
 Packaging Type Tray
 Panel Mount No
 Pitch - Mating Interface 5.00mm
 Pitch - Termination Interface 5.00mm
 Plating min - Mating 5.080µm
 Plating min - Termination 5.080µm
 Polarized to Mating Part Yes
 Stackable No
 Temperature Range - Operating -20° to +120°C
 Termination Interface: Style IDT or Pierce
 Wire Size AWG 18, 20

Electrical

Current - Maximum per Contact 10.0A
 Voltage - Maximum 250V AC

Material Info

Reference - Drawing Numbers

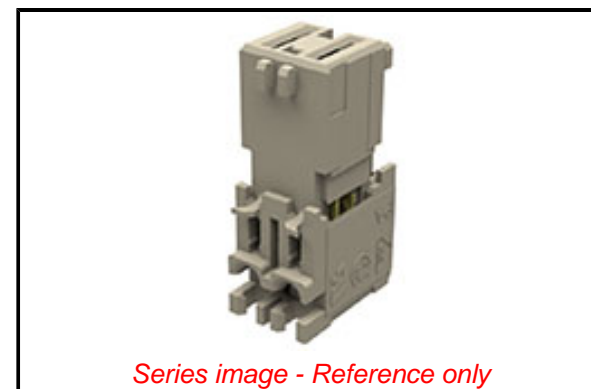

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 D(2022)4187-DC (10
 June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[91778 Series](#)

Mates With

[91999](#) , [93003](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
RAST 5 Power Semi-Automatic IDC Machine	2166580200
Hand Tool for Appli-Mate RAST 5 Connectors	638276300

Packaging Specification
Product Specification
Sales Drawing

PK-90833-001-001
PS-99020-0037-001
917780001-000

This document was generated on 11/23/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION