

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0512422000

Status:


Active

Overview:

MicroClasp Wire-to-Board System

Description:

2.00mm Pitch MicroClasp Wire-to-Board Receptacle Housing, Positive Lock, Dual Row, with Terminal Retainer Option, 20 Circuits, Natural

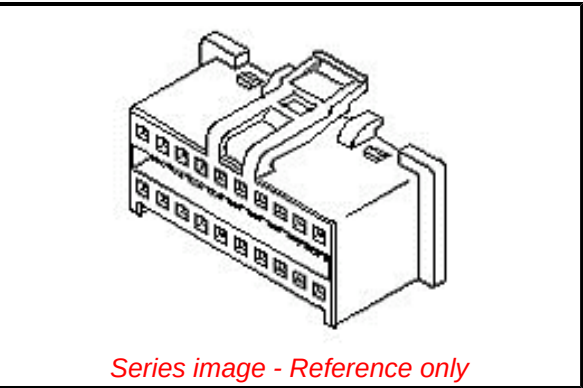

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-51242-002-001 (PDF)

Application Specification 561340000-AS-000 (PDF)

Packaging Specification 512429200-SPK-200 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	51242
Application	Signal, Wire-to-Board
Overview	MicroClasp Wire-to-Board System
Product Name	MicroClasp
Taxonomy	Connector Housings
UPC	800756188676
Physical	
Circuits (maximum)	20
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1319.500/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-25° to +85°C
Material Info	
Reference - Drawing Numbers	
Application Specification	561340000-AS-000
Packaging Specification	512429200-SPK-200
Product Specification	PS-51242-002-001
Sales Drawing	SD-51242-002-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2022)4187-DC (10

June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

51242 Series

Mates With

MicroClasp Header 55763

Use With

MicroClasp TPA Retainer 55767
 Crimp Terminal 56134
 MicroClasp Pre-Crimped Leads 797581001 , 797581002

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION