

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0511911000

Status:


Active

Overview:

Mini-Latch Wire-to-Board / Wire-to-Wire Connector System

Description:

2.50mm Pitch Mini-Latch Wire-to-Wire and Wire-to-Board Receptacle Housing, with Guide Rails, 10 Circuits

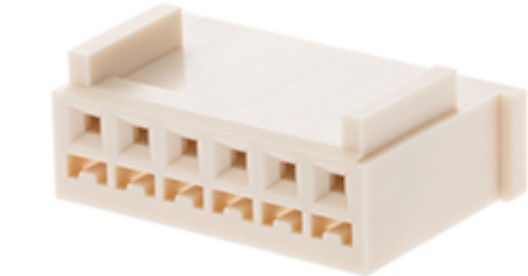

Series image - Reference only

Documents:

- 3D Model

Product Specification PS-51191-003-001 (PDF)
- Drawing (PDF)

Application Specification 511910000-AS-000 (PDF)
- 3D Model (PDF)

Packaging Specification 511919200-SPK-200 (PDF)
- Product Specification 2055050000-PS-000 (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification 511910000-PS-000 (PDF)

Agency Certification

UL

E29179

General

Product Family

Crimp Housings

Series

51191

Application

Signal, Wire-to-Board, Wire-to-Wire

Overview

Mini-Latch Wire-to-Board / Wire-to-Wire Connector System

Product Name

Mini-Latch

Taxonomy

Connector Housings

UPC

800753327863

Physical

Circuits (maximum)

10

Flammability

94V-0

Gender

Receptacle

Glow-Wire Capable

No

Material - Resin

Nylon

Net Weight

961.600/mg

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

2.50mm

Stackable

No

Temperature Range - Operating

-40° to +105°C

Material Info

Reference - Drawing Numbers

Application Specification

511910000-AS-000

Packaging Specification

511919200-SPK-200

Product Specification

2055050000-PS-000, 511910000-PS-000, PS-51191-003-001

Sales Drawing

SD-51191-004-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

51191 Series

Mates With

5045 Vertical Header . 5046 Right Angle Header . 5240 Plug Housing

Use With

50802 Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION