

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2157591004

Status:


Active

Overview:

Micro-Fit+ Connector System

Description:

Micro-Fit+ Receptacle Housing, Single Row, 4 Circuits, UL 94V-0, Glow-Wire Capable, Black

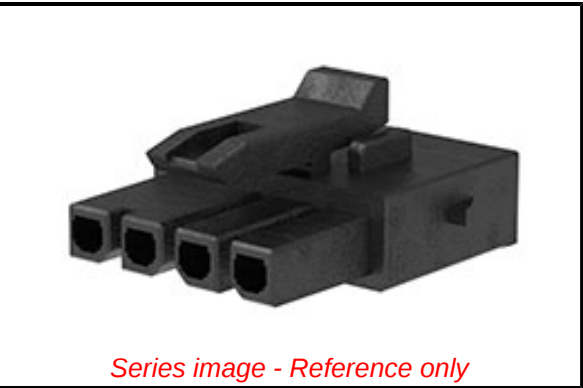

Documents:	
3D Model	Packaging Specification 2157590003-PK-000 (PDF)
Drawing (PDF)	Test Summary 2157590005-TS-000 (PDF)
3D Model (PDF)	Datasheet (PDF)
Product Specification 2064600000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification 2064600001-AS-000 (PDF)	

General	
Product Family	Crimp Housings
Series	215759
Application	Power, Wire-to-Board
Overview	Micro-Fit+ Connector System
Product Name	Micro-Fit+
Taxonomy	Connector Housings
UPC	193264919802
Physical	
Circuits (maximum)	4
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.563/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm
Pitch - Termination Interface	3.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	2064600001-AS-000
Packaging Specification	2157590003-PK-000
Product Specification	2064600000-PS-000
Sales Drawing	2157590002-000
Test Summary	2157590005-TS-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

215759 Series

Mates With

Micro-Fit+ Headers [216571](#) , [215760](#) , [218989](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION