

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0050579306

Status:


Active

Overview:

SL Modular Connectors

Description:

SL Crimp Housing, Single Row, Version D, Back Ribs, 6 Circuits, Black

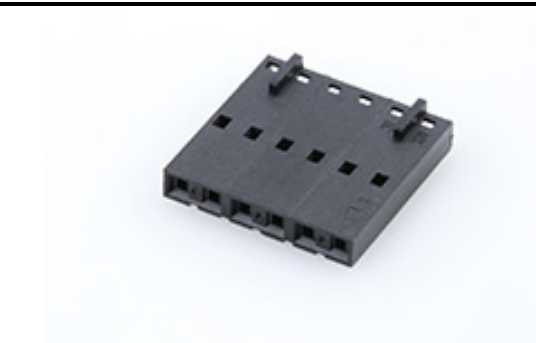

Series image - Reference only

Documents:	
3D Model (PDF)	Product Specification PS-71851-001 (PDF)
Drawing (PDF)	Packaging Specification PK-70066-100-001 (PDF)
3D Model	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-70400-001 (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70066
Application	Signal, Wire-to-Board
Comments	Version D
Overview	SL Modular Connectors
Product Name	SL
Taxonomy	Connector Housings
UPC	800753724822
Physical	
Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	No
Material - Resin	Polyester Alloy
Net Weight	0.044/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	70066-0110
Reference - Drawing Numbers	
Packaging Specification	PK-70066-100-001
Product Specification	PS-70058-001, PS-70400-001, PS-71851-001
Sales Drawing	SD-70066-0106-0129-001
Test Summary	TS-70058-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

70066 Series

Mates With

70004 Interim Clip, 70013 , 70022 , 70104 , 70475 , 70431 , 70543 , 70553

Use With

SL Crimp Terminal 70021 , 70058 , 71851

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION