

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0469990805

Status:


Active

Overview:

Standard .062"+ and Standard .062" Pin and Socket Connector Systems

Description:

1.57mm Diameter Standard .062" Pin and Socket Receptacle Housing, 6 Circuits, with Pre-bent Mounting Ears, Natural

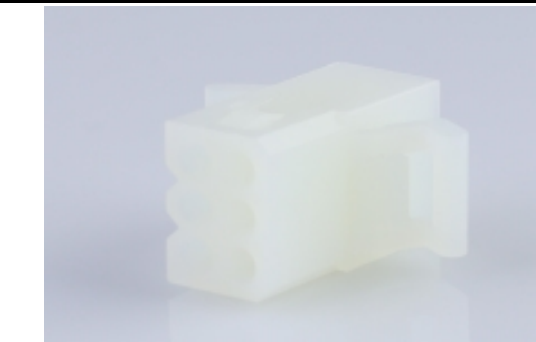

Series image - Reference only

Documents:	
3D Model	Packaging Specification PK-1625-003-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Drawing (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	1625
Application	Power, Wire-to-Wire
Overview	Standard .062"+ and Standard .062" Pin and Socket Connector Systems
Product Name	Standard .062"
Taxonomy	Connector Housings
UPC	889056852449
Physical	
Circuits (maximum)	6
Circuits Detail	2x3
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.867/g
Number of Rows	3
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	3.68mm
Pitch - Termination Interface	3.68mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Electrical	
Current - Maximum per Contact	5.0A
Material Info	
Engineering Number	1625-6R2
Reference - Drawing Numbers	
Packaging Specification	PK-1625-003-001
Sales Drawing	16250600-SD-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

1625 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION