

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2053410204

Status:


Active

Overview:

Pico-Lock Connector System

Description:

2.00mm Pitch, Pico-Lock Receptacle Crimp Housing, Single Row, Positive Lock, 4 Circuits, Black

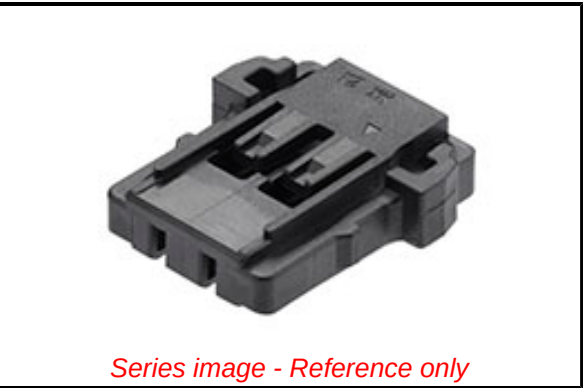

Documents:	
3D Model	Application Specification 2053410000-AS-000 (PDF)
Drawing (PDF)	Packaging Specification 2053419200-SPK-200 (PDF)
3D Model (PDF)	Datasheet (PDF)
Product Specification 2053410000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	205341
Application	Signal, Wire-to-Board
Overview	Pico-Lock Connector System
Product Name	Pico-Lock
Taxonomy	Connector Housings
UPC	191130509997
Physical	
Circuits (maximum)	4
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyamide
Net Weight	146.370/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	2053410000-AS-000
Packaging Specification	2053419200-SPK-200
Product Specification	2053410000-PS-000
Sales Drawing	2053410000-SD-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

205341 Series

Mates With

Pico-Lock PCB Header [205338](#)

Use With

Pico-Lock Crimp Terminal [205342](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION