

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0350230014

Status:

Active

Overview:

Board-in Connectors


Description:

2.00mm Pitch, Board-In Crimp Housing, Right-Angle, 14 Circuits, Natural

Documents:	
3D Model	Product Specification PS-35023-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-35023-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification		
CSA		LR19980
UL		E29179
General		
Product Family		Crimp Housings
Series		35023
Application		Signal, Wire-to-Board
Overview		Board-in Connectors
Product Name		Board-in
Taxonomy		Connector Housings
UPC		800753576575
Physical		
Circuits (maximum)		14
Color - Resin		Natural
Flammability		94V-0
Gender		N/A
Glow-Wire Capable		No
Material - Resin		Nylon
Net Weight		0.273/g
Number of Rows		1
Packaging Type		Bag
Panel Mount		No
Pitch - Mating Interface		2.00mm
Stackable		No
Temperature Range - Operating		-40° to +105°C
Solder Process Data		
Lead-freeProcess Capability		N/A

Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-35023-001-001
Product Specification	PS-35023-001-001
Sales Drawing	SD-35023-001-001

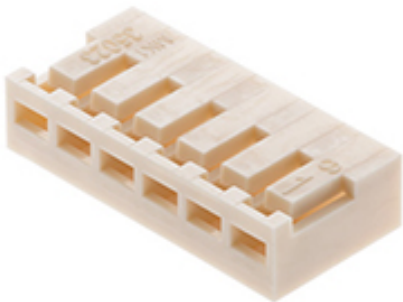

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

35023 Series

Use With

Straight Terminal [350449102](#) , [350449260](#)

Right Angle Terminal [350211201](#) ,
[350211301](#) , [350211360](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION