

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


0351840300

Status:

Active

Description:

2.50mm Pitch Wire-to-Wire Plug Housing, Natural, 3 Circuits

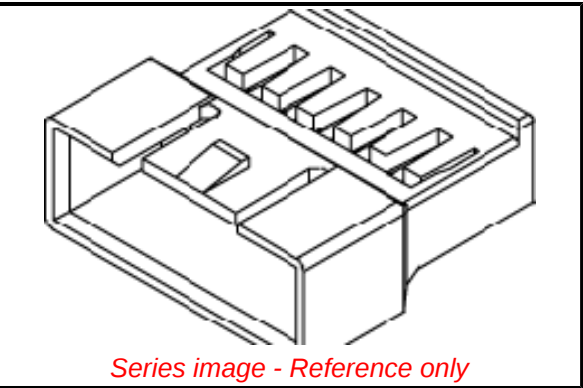

Documents:	
3D Model	Product Specification PS-35184-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-35184-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-35053-001-001 (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	35184
Application	Signal, Wire-to-Wire
Product Name	N/A
Taxonomy	Connector Housings
UPC	800754253352
Physical	
Breakaway	No
Circuits (maximum)	3
Color - Resin	Natural
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.593/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Pitch - Termination Interface	2.50mm
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-35184-001-001
Product Specification	PS-35053-001-001, PS-35184-001-001
Sales Drawing	SD-35184-XX0X-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

35184 Series

Mates With

35155 Wire-to-Board Housing, 35572 Wire-to-Wire and Wire-to-Board Housing

Use With

35053 Wire-to-Wire Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION