

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0009507041

Status:

Active

Overview:

KK Interconnect Systems

Description:

KK 3.96mm Crimp Terminal Housing, 4 Circuits, Natural

Documents:

3D Model


Drawing (PDF)

3D Model (PDF)

Product Specification PS-08-50-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	2139
Application	Power, Wire-to-Board
Overview	KK Interconnect Systems
Product Name	KK 396
Taxonomy	Connector Housings
UPC	800753531505
Physical	
Circuits (maximum)	4
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	1.024/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Temperature Range - Operating	See Product Specification
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	2139-4C
Reference - Drawing Numbers	
Product Specification	PS-08-50-001
Sales Drawing	SD-2139-001, SD-2139-002

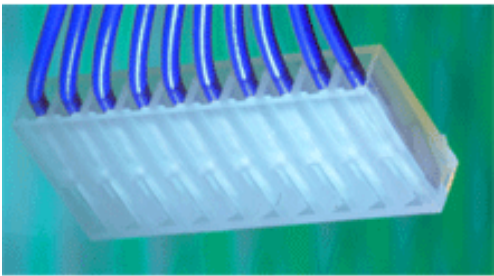

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

2139 Series

Mates With

KK 396 Headers: 41771 , 41772 , 41791 , 41792 , 42491 , 42492 , KK 396 Breakaway Headers: 41661 , 41662 , 41671 , 41672

Use With

2478 Crimp Terminals for 18-24 AWG, 2578 Crimp Terminals for 22-26 AWG

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION