

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0350220010

Status:


Active

Overview:

Board-in Connectors

Description:

2.50mm Pitch, Board-In Crimp Housing, Single Row, Right-Angle and Vertical, 10 Circuits, Natural

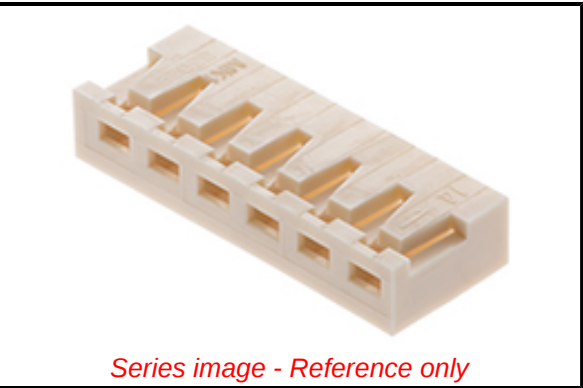

Series image - Reference only

Documents:	
3D Model	Product Specification PS-35022-003-001 (PDF)
Drawing (PDF)	Packaging Specification PK-35022-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-35021-001-001 (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	35022
Application	Signal
Overview	Board-in Connectors
Product Name	Board-in
Taxonomy	Connector Housings
UPC	800753576964
Physical	
Circuits (maximum)	10
Color - Resin	Natural
Flammability	94V-0
Gender	N/A
Glow-Wire Capable	No
Lock to Mating Part	None
Material - Resin	Nylon
Net Weight	0.253/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-35022-001-001
Product Specification	PS-35021-001-001, PS-35022-003-001
Sales Drawing	SD-35022-00XX-001

EU ELV Compliant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS ELV	Green Image Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
35022 Series

Use With
Straight Terminal [350449105](#)
Right
Angle Terminal [350211001](#) , [350211160](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION