

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0350230008

Status:

Active

Overview:

Board-in Connectors

Description:

2.00mm Pitch, Board-In Crimp Housing, Right-Angle, 8 Circuits, Natural

Documents:	
3D Model	Product Specification PS-35023-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-35023-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	35023
Application	Signal, Wire-to-Board
Overview	Board-in Connectors
Product Name	Board-in
Taxonomy	Connector Housings
UPC	800753514515

Physical

Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-0
Gender	N/A
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	0.151/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40° to +105°C


Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35023-001-001
Product Specification	PS-35023-001-001
Sales Drawing	SD-35023-001-001

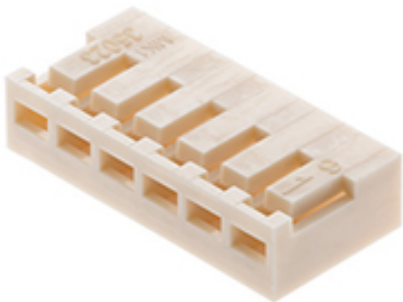

Series image - Reference only

EU ELV
Compliant

EU RoHS
Compliant
REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free
Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
35023 Series

Use With
Straight Terminal [350449102](#) , [350449260](#)

Right Angle Terminal [350211201](#) ,
[350211301](#) , [350211360](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION