


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0350220008](#)
Status: **Active**
Overview: [Board-in Connectors](#)
Description: 2.50mm Pitch, Board-In Crimp Housing, Single Row, Right-Angle and Vertical, 8 Circuits, Natural

Documents:

3D Model	Product Specification PS-35022-003-001 (PDF)
3D Model (PDF)	Packaging Specification PK-35022-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-35021-001-001 (PDF)	

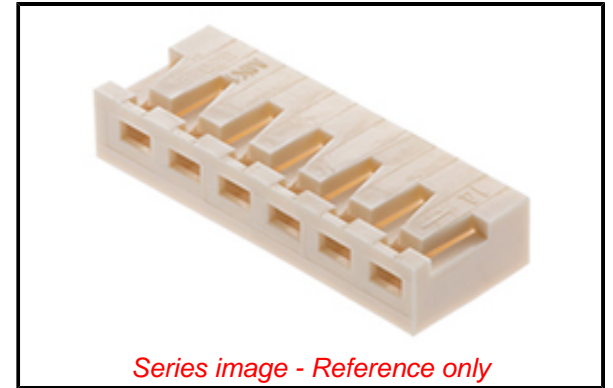

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	35022
Application	Signal
Overview	Board-in Connectors
Product Name	Board-in
Taxonomy	Connector Housings
UPC	800753876644

Physical

Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-0
Gender	N/A
Glow-Wire Capable	No
Lock to Mating Part	None
Material - Resin	Nylon
Net Weight	0.200/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C

Solder Process Data

Lead-freeProcess Capability	N/A
-----------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35022-001-001
Product Specification	PS-35021-001-001, PS-35022-003-001
Sales Drawing	SD-35022-00XX-001

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[35022](#) Series

Use With

Straight Terminal [350449105](#)
Right
Angle Terminal [350211001](#) , [350211160](#)