

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0350230002

Status:

Active

Overview:


Board-in Connectors

Description:

2.00mm Pitch, Board-In Crimp Housing, Right-Angle, 2 Circuits, Natural

Documents:	
3D Model	Product Specification PS-35023-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-35023-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	35023
Application	Signal, Wire-to-Board
Overview	Board-in Connectors
Product Name	Board-in
Taxonomy	Connector Housings
UPC	800753576551
Physical	
Circuits (maximum)	2
Color - Resin	Natural
Flammability	94V-0
Gender	N/A
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	0.040/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-35023-001-001
Product Specification	PS-35023-001-001

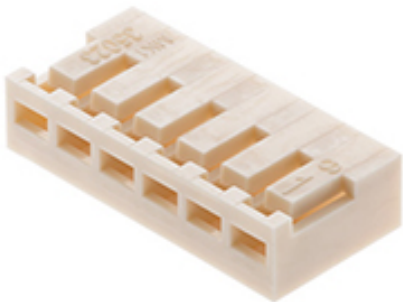

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series
35023 Series

Use With
Straight Terminal [350449102](#) , [350449260](#)

Right Angle Terminal [350211201](#) ,
[350211301](#) , [350211360](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION