

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2124150200

Status:

Active

Overview:

Board-in Connectors

Description:

2.50mm Pitch, Board-In Crimp Housing, 2 Circuits, Right-Angle, Natural


Documents:	
3D Model	Product Specification 2124150000PS-000 (PDF)
Drawing (PDF)	Packaging Specification 2124150000PK-000 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	212415
Application	Signal, Wire-to-Board
Overview	Board-in Connectors
Product Name	Board-in
Taxonomy	Connector Housings
UPC	193264513635
Physical	
Circuits (maximum)	2
Color - Resin	Natural
Gender	N/A
Glow-Wire Capable	No
Material - Resin	Polyamide
Net Weight	0.062/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Crimp Specification	350210000CS-000
Packaging Specification	2124150000PK-000
Product Specification	2124150000PS-000
Sales Drawing	2124150000-000

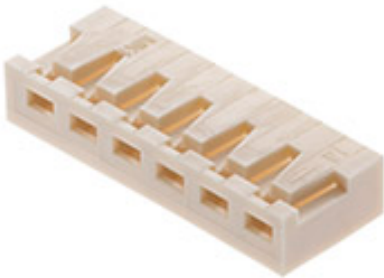

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2022)4187-DC (10
June 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[212415](#) Series

Use With

2.50mm Pitch Board-In Crimp Terminal
[350211001](#) , [350211160](#)