


Outdoor Luminaire – GARTIA Instruction Manual

MEGATRON®

TECHNICAL SPECIFICATION:

| | |
|--------------|---------------|
| Series Name | GARTIA SCHIRM |
| Model Number | MT70804 |
| Color | Graphite |
| Lamp Holder | GU10 |
| Lamp Wattage | max. 20W |
| Voltage | 220-240V- AC |
| Frequency | 50/60 Hz |
| IP Rating | IP65 |

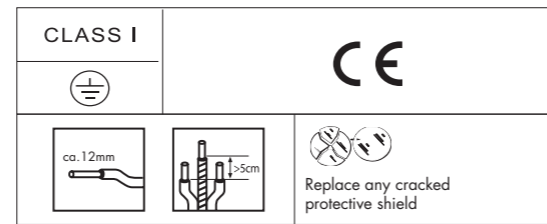


CAUTIONS:

- Read the entire manual carefully before installation and operation.
- Installation or replacement should be performed only by licensed and qualified electricians.
- DO NOT disassemble the inner part of the luminaire. Doing so may result in luminaire damage or malfunction.
- Switch OFF the power source before installation, replacement and cleaning! ⚠
- Before replacement of the lamp or luminaire, turn it off and allow it to cool down. Heat-resistant gloves are mandatory when handling the luminaire.
- The manufacturer accepts no liability for any damage resulting from the misuse of the luminaire or from when it is used with inappropriate equipment.
- Important warning for ground drilling and drilling in walls: before drilling, make sure that there are no gas and water pipes or power lines behind or near the drilling spots. Drilling and mounting should be performed only by qualified personnel. Be sure to pay attention to the condition and material of the ground and walls, as the supplied mounting material is not suitable for all ground and wall types. Please inquire about recommended screws and raw plugs for your ground or wall type and condition. The manufacturer accepts no liability for improper wall raw plug mounting and the herefrom resulting damages.
- Consult your dealer if you have any enquiries.

ATTENTION:

- Instant start is allowed.
- Designed for outdoor applications.
- The operating temperature of the luminaire is -25° C to +45° C.


INSTALLATION with spike:

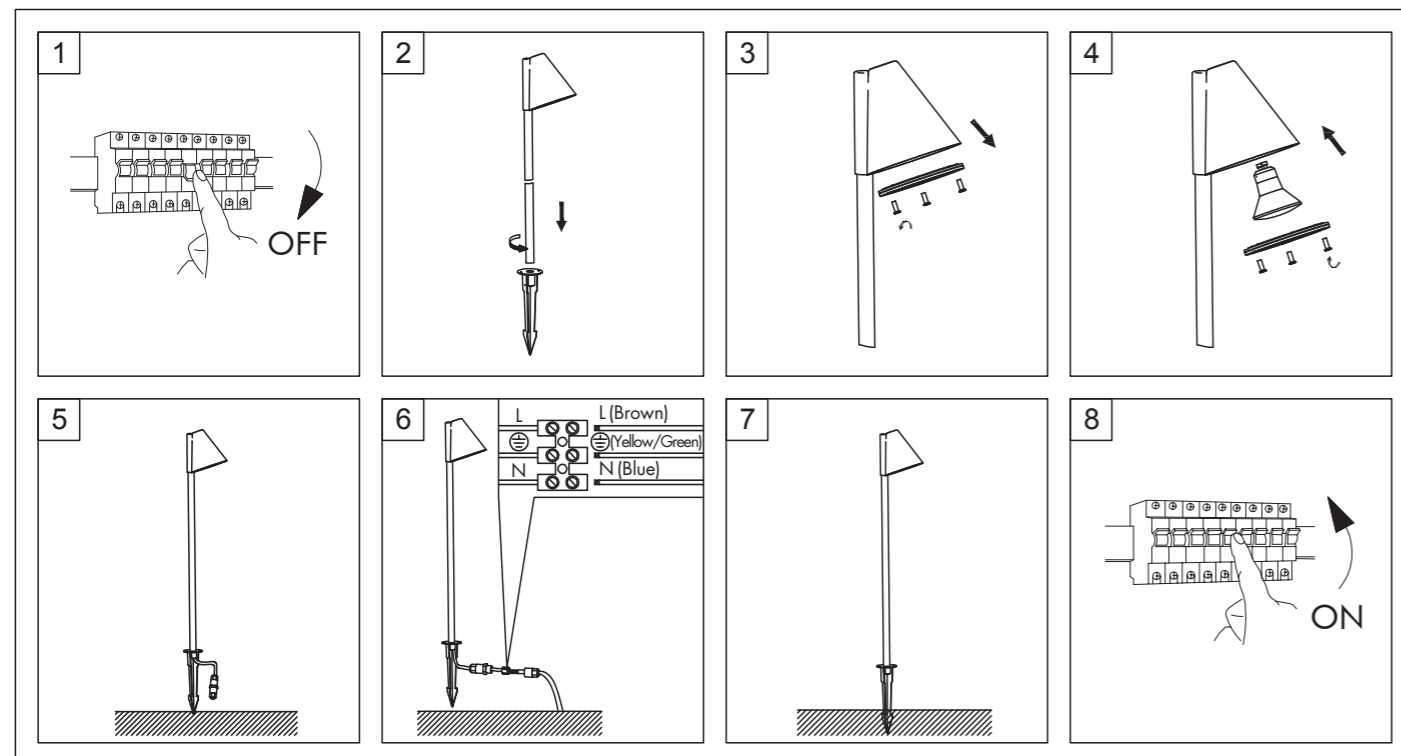

Outdoor Luminaire – GARTIA Instruction Manual

MEGATRON®

INSTALLATION with base plate:

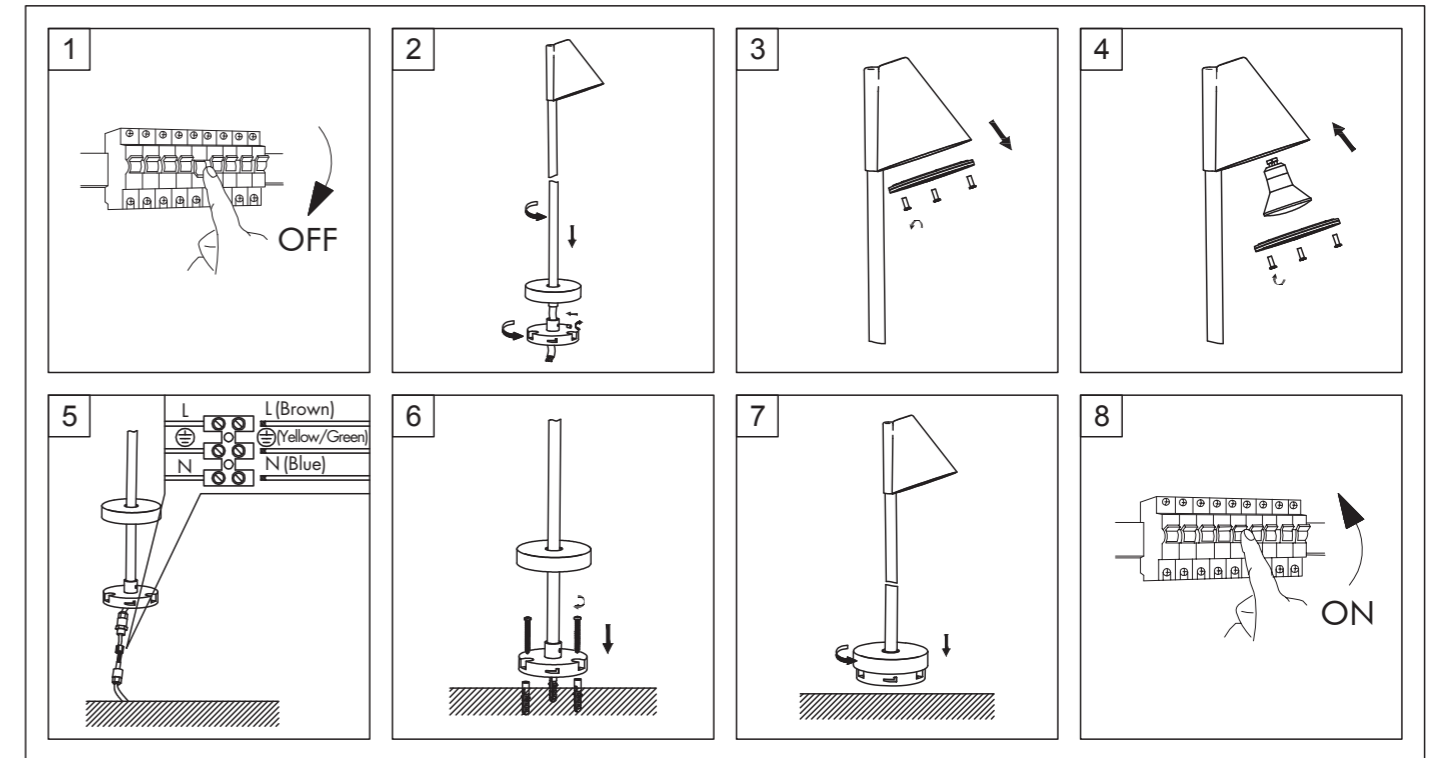

Correct disposal of this product:

This marking indicates that this product should not be disposed with other household wastes throughout the EU. To prevent possible harm to the environment or human health from uncontrolled waste disposal, recycle it responsibly, to promote the sustainable reuse of material resources. To return your device, please use the return and collection systems, or contact the retailer where the product was purchased. They can take this product for environmental safe recycling.