

LED Bathroom Recessed Ceiling Fixture GX53 – AQUA

Instruction Manual

TECHNICAL SPECIFICATION:

Series Name	AQUA			
Model Number	LM85660	LM85661	LM85664	LM85665
Color	Chrome	Silver leaf	Chrome	Silver leaf
Lamp Holder	GX53			
Incl. Lamp	3 x LM85480	3 x LM85481	LM85480	LM85481
Lamp Wattage	3 x 6W	3 x 6W	6W	6W
Total Luminous Flux	3 x 500lm	3 x 500lm	500lm	500lm
Voltage	220-240V~			
Frequency	50Hz			
IP Rating	IP44			


CAUTIONS:

- Read the entire manual carefully before installation and operation.
- Installation or replacement should be performed only by licensed and qualified electricians.
- DO NOT disassemble the inner part of the luminaire. Doing so may result in luminaire damage or malfunction.
- Switch OFF the power source before installation, replacement and cleaning! ⚠
- Wearing gloves during installation is recommended to ensure the luminaire is kept in the best condition.
- Before replacement of the lamp or luminaire, turn it off and allow it to cool down. Heat-resistant gloves are mandatory when handling the luminaire.
- The manufacturer accepts no liability for any damage resulting from the misuse of the luminaire or from when it is used with inappropriate equipment.
- Consult your dealer if you have any enquiries.
- Important warning for drilling in walls: before drilling, make sure that there are no gas and water pipes or power lines behind or near the drilling spots. Drilling and mounting should be performed only by qualified personnel. Be sure to pay attention to the condition and material of the walls, as the supplied mounting material is not suitable for all wall types. Please inquire about recommended screws and raw plugs for your wall type and wall condition. The manufacturer accepts no liability for improper wall raw plug mounting and the herefrom resulting damages.



ATTENTION:

- Instant start is allowed.
- The luminaire may only be used with GX53 LED lamps!
- IP44 waterproof protection, designed for indoor applications.
- The operating temperature of the luminaire is -20°C to +40°C.

INSTALLATION (LM85660,LM85661,LM85664,LM85665)

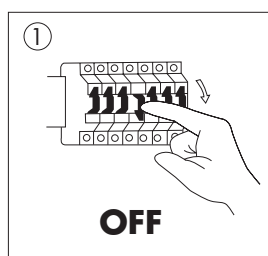

1. Turn OFF the power.
2. Drill the 90mm-diameter cut hole in the ceiling.
3. + 4. Connect the cable to the terminal block.
5. Insert the luminaire in the drilled cut hole.
6. Insert the lamp LM85480/LM85481 into the lamp holder.
7. Turn ON the power.

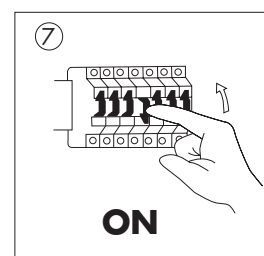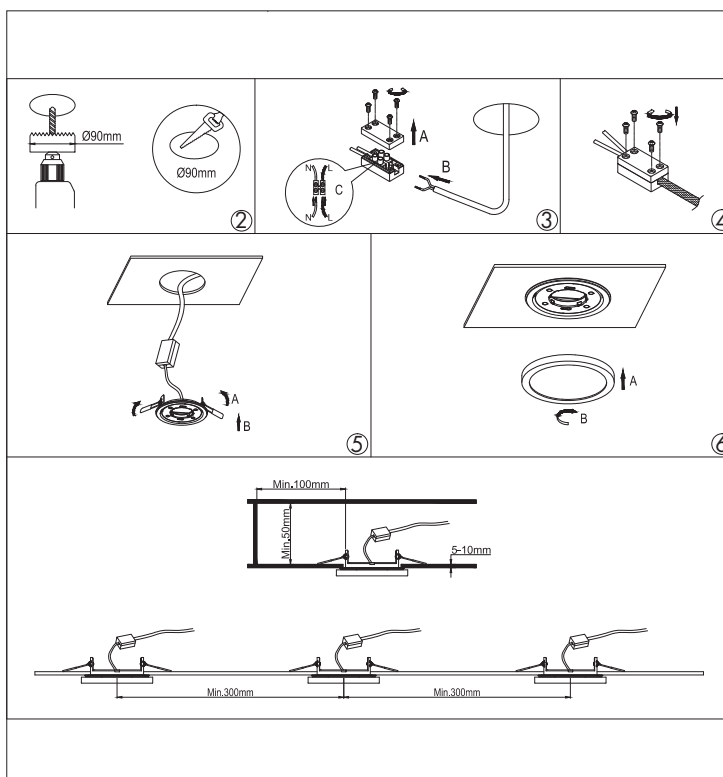

Correct disposal of this product:



This marking indicates that this product should not be disposed with other household wastes throughout the EU. To prevent possible harm to the environment or human health from uncontrolled waste disposal, recycle it responsibly, to promote the sustainable reuse of material resources. To return your device, please use the return and collection systems, or contact the retailer where the product was purchased. They can take this product for environmental safe recycling.

