



Order Code	TCK-112
Inductance	12 $\mu\text{H} \pm 20\%$ (at 100 kHz / 250 mV)
Impedance (DCR)	53 m Ω max.
Rated Current	4 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions

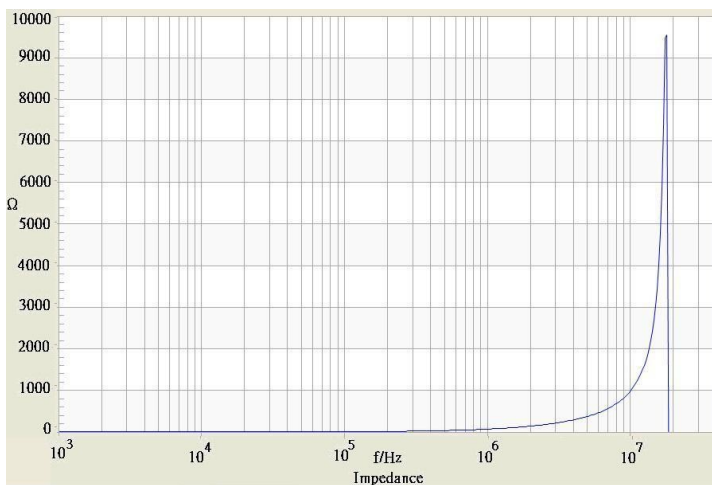

Impedance Curve



Outline Dimensions

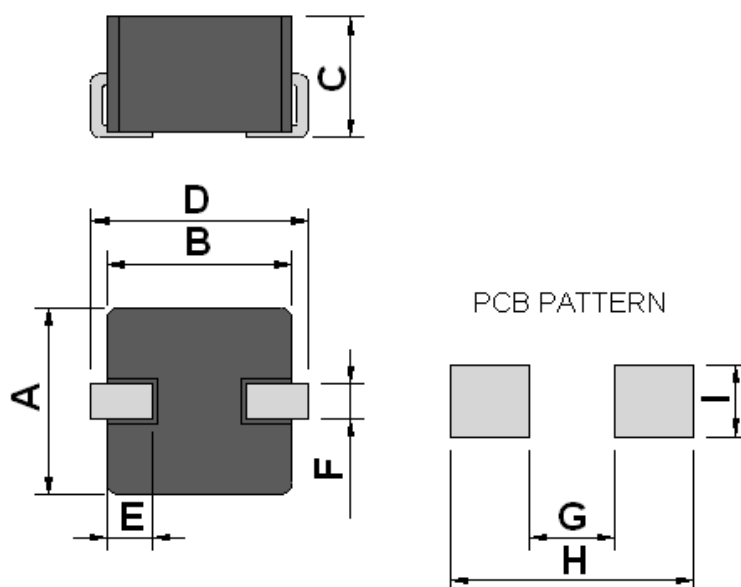

Dimensions [mm]	
A	6.5 ± 0.2
B	6.5 ± 0.2
C	3.85 ± 0.15
D	7.6 max.
E	1.5 ± 0.3
F	1.2 ± 0.3
G	3.0
H	8.5
I	2.5

All specifications valid at +25°C, unless otherwise stated.