



MI.PUCK DIMMERS

müller EA 27.11 pro4 mi.puck mini led strip dimmer

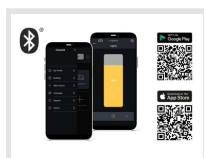

mi.puck-App

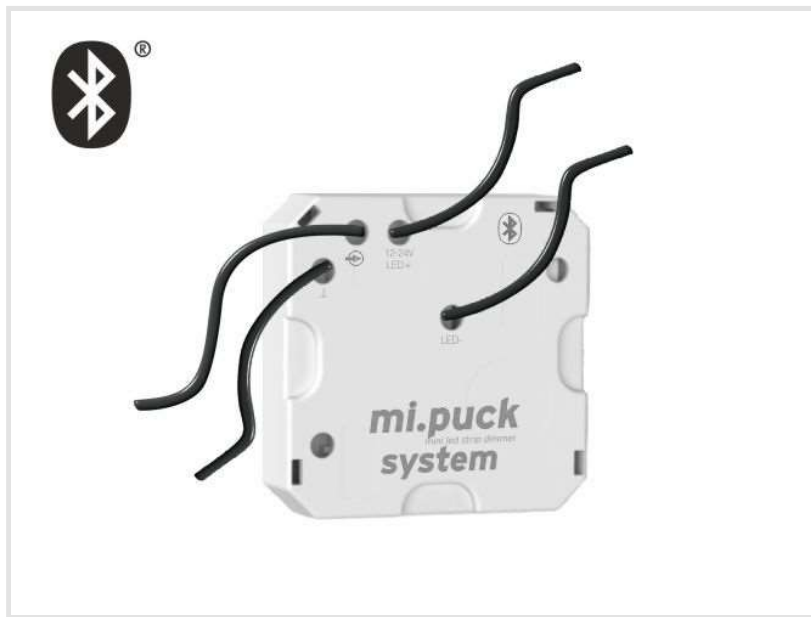

müller LS 20.00 pro4 mi.sensor

Overview

- Astro dimmer (remote-controllable)
- Dimmer for dimmable LED strips
- Minimum and maximum dimming-value adjustable
- Adjustable switch-on dimming-value or memory function
- Staircase lighting function
- Integrated Bluetooth
- mi.system mesh
- Programmable and controllable via app (iOS and Android)
- Switching program can be deactivated via app
- Compact insert housing for flush-mounting
- Protection against overload, overvoltage, short circuit and overheat

App to manage the mi.system:

mi.puck App (Apple App Store)

(<https://apps.apple.com/us/app/mi-puck/id1590845051>)

mi.puck (<https://itunes.apple.com/us/app/saven-carry/id1347128572?mt=8>) App (Google Play Store)

(<https://play.google.com/store/apps/details?id=de.hugomueller.mi.control>)

Order numbers

■ müller

EA 27.11 pro4

Bluetooth control
Led-strip dimmer
Remote Control

MI.PUCK DIMMERS

müller EA 27.11 pro4 mi.puck mini led strip dimmer

Order information

	EAN	Art. No.
EA 27.11 pro4	4022709243843	24384

Technical data

Supply voltage	12-24V DC
Power consumption (real power)	>0,15 W at 24V
LED strips (12-24V DC)	8 A at 25°C 7 A at 35°C 6 A at 45°C
Transmission type	Bluetooth LE Range max. 75 m
Switching functions	Astro - ON/OFF Night - ON/OFF Extra - ON/OFF Permanent - ON/OFF
Offset Astro switching time	+/-90min.
Memory locations	100
Time base	Quarz
Quartz accuracy	±0,5 Sek./day (Quartz accuracy optimized for typical ambient conditions)
Program security	unlimited
Permitted ambient temperature	-25...+45 °C
Housing	self-extinguishing thermoplastic
Mounting	Flush-mounting (preferably combined with hollow-wall box)
Type of connection	With litz wires
Class of protection	III when installed according to regulations
Minimum requirement	Android version 7.0 iOS version 12.0 Bluetooth 4.0
Accessories (free download)	Programmable and controllable with smartphone via Bluetooth: App - mi.puck

Rights to technical amendments reserved / Technische Änderungen vorbehalten
Droits de modifications techniques réservés / Suscettibile di errori e modifiche

