

AUDIO INTERFACES


müller AS 36.x3 knx



Accessories



Loudspeaker LA
06.10

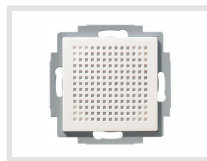

Loudspeaker LA
16.10

Overview

- Chime / door bell for building automation KNX
- 6 individual MP3-files can be uploaded via ETS
- 12 pre-defined tones/melodies
- 3 binary inputs
- 10 input objects and 16 scenes can be configured
- External loudspeaker can be connected
- Small external loudspeaker (LA 06.10) included in delivery (AS 36.13 knx)
- Adjustable volume level
- No auxiliary supply needed
- Day/night mode function
- Mute function
- Clearly structured ETS
- Easy handling and mounting
- Flush-mounted fitting
- Compact housing
- Can be installed behind any kind of blind cover or also behind a switch/pushbutton in a long mounting box!

Order numbers

■ müller

AS 36.03 knx

AS 36.13 knx

Audio interface
without loudspeaker
Audio interface
with loudspeaker

AUDIO INTERFACES

müller AS 36.x3 knx

Order information

	EAN	Art. No.
AS 36.03 knx	4022709242419	24241
AS 36.13 knx	4022709242426	24242

Technical data

Supply voltage	via KNX bus voltage
Bus current	< 12 mA without output signal < 20 mA with output signal
Bus system	KNX
Input	3 binary inputs
Output	1 speaker output
Volume level	11 volume steps
Speaker output	max. 0,45 W
Impedance ext. speaker	4-8 Ohm
Melodies	6 own MP3-files 12 preset tones
Applikation software	ETS5 or higher
Permitted ambient temperature	-10...+45 °C
Housing	self-extinguishing thermoplastic
Dimensions AS 36.03 knx	44 x 41,5 x 20 mm
Dimensions loudspeaker	∅ 60 mm incl. mounting ring
Housing color	studio white (similar to RAL 9016) specific colors on request
Mounting	flush-mounting
Type of connection	KNX-Connector screw-type terminals (for in-/outputs)
Type of protection	IP20 according to DIN EN 60529
Class of protection	III when installed according to regulations

Rights to technical amendments reserved / Technische Änderungen vorbehalten
Droits de modifications techniques réservés / Suscettibile di errori e modifiche

