



## LED indicator 12V DC, Red



|                       |                       |  |  |
|-----------------------|-----------------------|--|--|
| Rating                | 12V DC                |  |  |
| Insulation Resistance | DC 500V 100M ohm Min. |  |  |
| Dielectric Strength   | AC 1500V 1 minute     |  |  |
| Operation Temperature | -20°C~+85°C           |  |  |
|                       |                       |  |  |

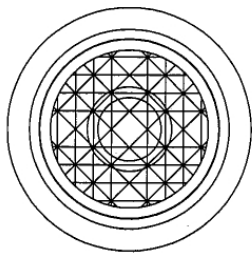

Material:  
Frame: Black,nylon 66  
Lens: Red,PC  
Terminals: Tin plated brass  
LED: Red

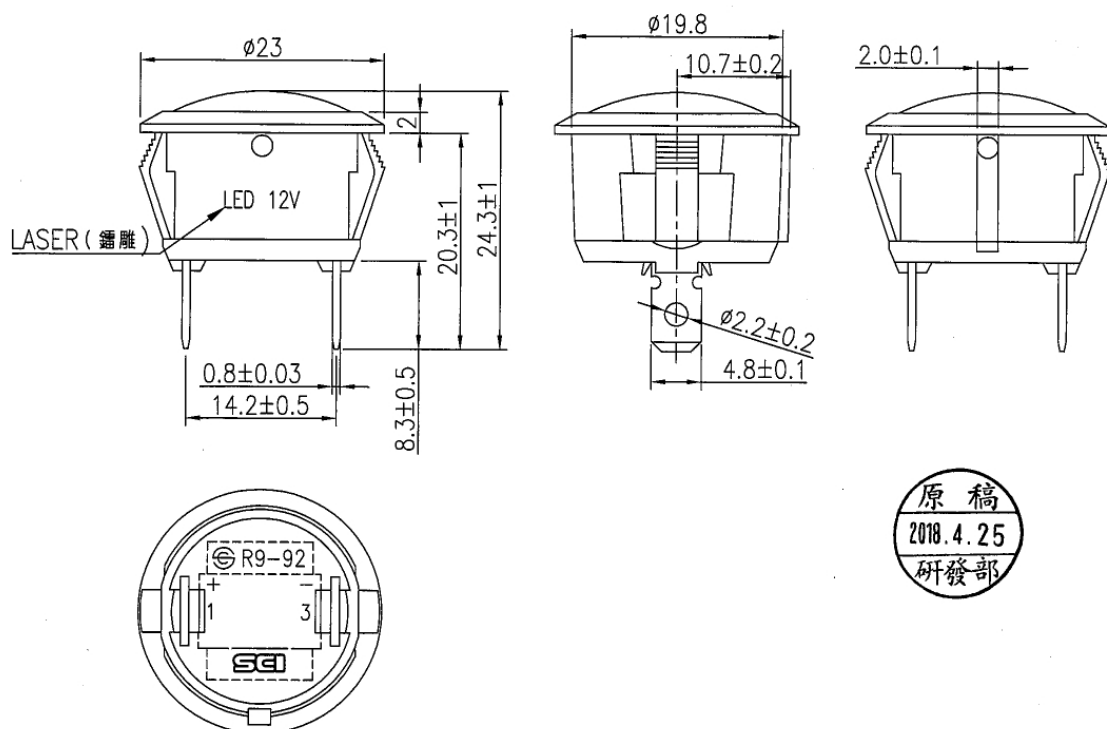

Tolerances  $\pm 0.3$  Unless Otherwise Specified