

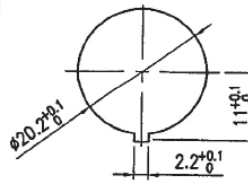


Data Sheet

LED indicator 24V DC, Amber

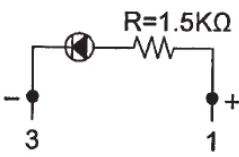

Rating	24V DC	Mounting Hole	Circuit Diagram
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20°C~85°C		

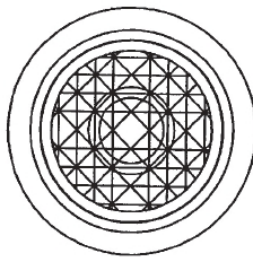

Material:

Frame: black, nylon 66

Lens: yellow, PC

Terminals: tin plated brass

LED: yellow

