


Data Sheet

LED indicator 12V DC, Blue



Rating	12V DC		
Insulation Resistance	DC 500V 100M ohm Min.		
Dielectric Strength	AC 1500V 1 minute		
Operation Temperature	-20°C~85°C		

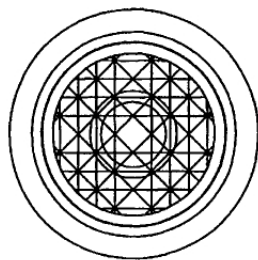

Material:
Frame: black,nylon 66
Lens: blue,PC
Terminals: tin plated brass
LED: blue

