

## Fiber Simplex Patch Cable SC/APC-LC/APC Polish

### Technical Features


SC/APC-LC/APC polish

OS2 9/125  $\mu\text{m}$ , compliant with G.657.A2

Jacket: LSZH, yellow,  $\varnothing$ 2 mm


Test report included

### Technical Drawings

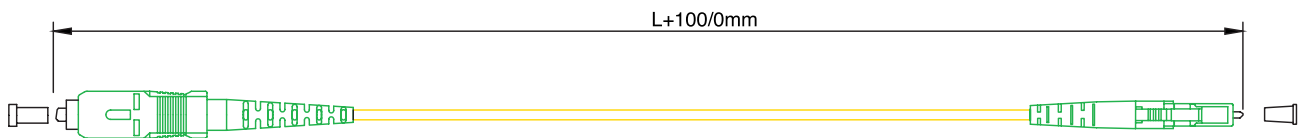

Test Grade Designation: Each to Reference		
Grade IL/RL	Standard	
Insertion Loss (IL)	$\leq 0,3\text{dB}$	IEC 61300-3-4
Return Loss(RL)	APC $\geq 60\text{dB}$	IEC 61300-3-6
Test Wavelength	1310nm	
End face inspection	x400	

Length	SC/APC-LC/APC	EAN Code
0.50 m	FPSLS00	4052792066142
1.00 m	FPSLS01	4052792066159
2.00 m	FPSLS02	4052792066166
3.00 m	FPSLS03	4052792066173
5.00 m	FPSLS05	4052792066180
10.00 m	FPSLS10	4052792066197
15.00 m	FPSLS15	4052792066203
20.00 m	FPSLS20	4052792066210

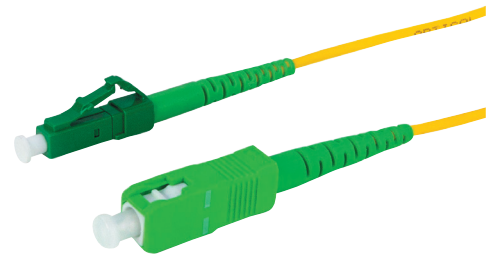

## Package Contents

1 x Fiber Simplex Patch Cable

## Packaging Information

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
FPSLS00	18x18x2 mm	0,011 kg	450x250x235 mm	300 pcs	4,035 kg
FPSLS01	18x18x2 mm	0,013 kg	450x250x235 mm	250 pcs	3,92 kg
FPSLS02	18x18x4 mm	0,016 kg	450x250x235 mm	200 pcs	3,98 kg
FPSLS03	22x22x4 mm	0,02 kg	450x250x235 mm	160 pcs	3,89 kg
FPSLS05	22x22x6 mm	0,027 kg	450x250x235 mm	60 pcs	2,328 kg
FPSLS10	22x22x6 mm	0,044 kg	450x250x235 mm	60 pcs	3,378 kg
FPSLS15	22x22x8 mm	0,062 kg	450x250x235 mm	50 pcs	3,81 kg
FPSLS20	22x22x8 mm	0,079 kg	450x250x235 mm	40 pcs	3,892 kg



Made in China

www.2direct.de 

\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.