

## DATASHEET

Item No.: 2813277

Type designation: LR6 Common: AA

Chemical system: Alkaline


Nominal voltage: 1.5 V

Weight: Approximate 23.8 g

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Dimension (mm)

/	min	max
$\Phi$	13.7	14.5
A	49.5	50.5
C	7.0	-
F	-	5.5
G	1.0	-

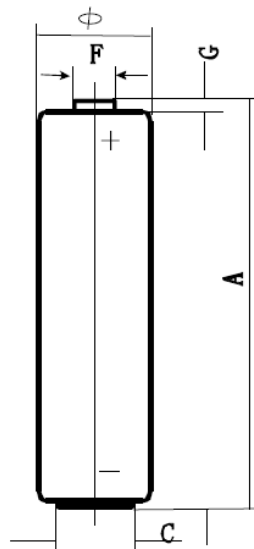

Capacity: 3000 mAh (10 mA, 24 h/d, 20°C, end voltage = 0.8 V)

Operating temperature: -18°C ~ 50°C

Recommend storage temperature: 20°C  $\pm$  2°C

Shelf lifetime: 7 Years