


# TY-RAP® with label cable tie with steel lug lock

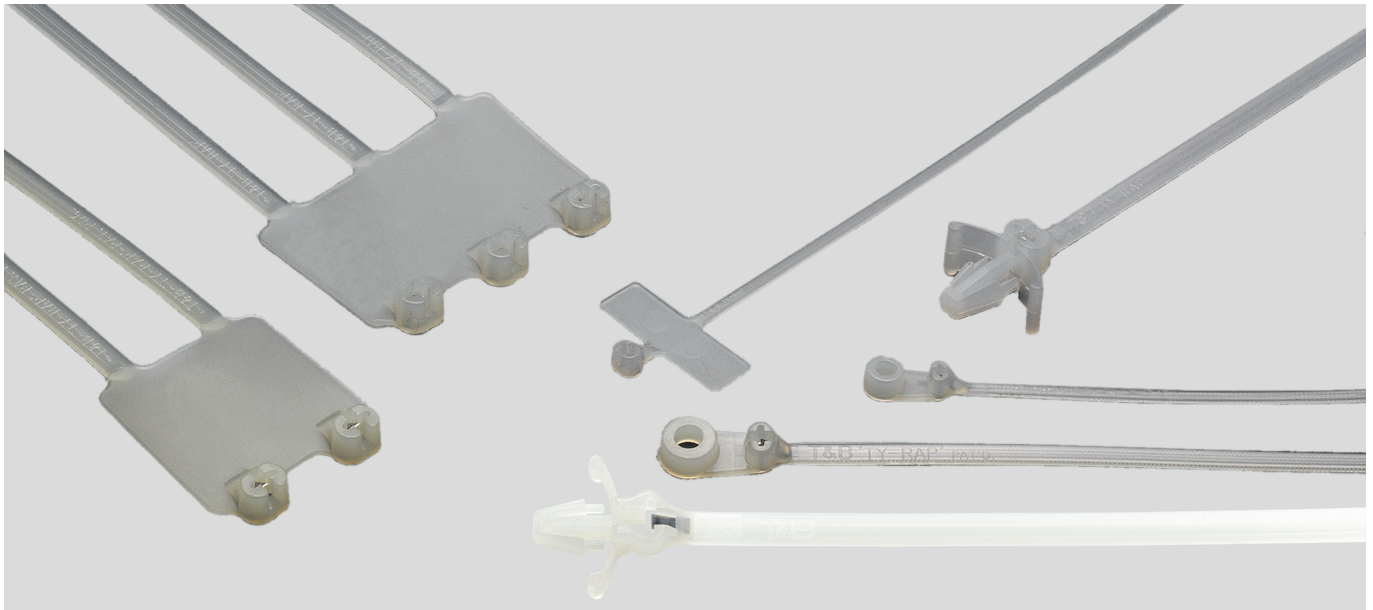

## TY-RAP®

Cable tie with steel lug lock made of corrosion-resistant, non-magnetic steel. This technology enables the cable tie to offer excellent binding properties even under the most rigorous conditions such as heat, cold, humidity etc. and makes it insensitive to vibrations and external influences.

## Material

Polyamide 6.6

- halogen-free
- silicone-free

## Note

TY-RAP® (special types)

## Technical data

Temperature range: -60°C up to +85°C

Flammability acc. to UL 94: V2

### marking area below the latch

Part no. transparent	Type	Colour	Length mm	Width mm	Bundle Ø mm	Capacity N	Hole Ø mm	Field W x H	Unit	Net EUR/100 items at a purchase of		
										up to 1000	1001 - 5000	5001 - 10000
91108	TY 51M	transparent	92,0	2,4	16,0	80	-	25.4 x 7.9	500	o. r.	o. r.	o. r.
91109	TY 512M	transparent	210,0	2,4	51,0	80	-	25.4 x 7.9	1000	o. r.	o. r.	o. r.
91110	TY 48M	transparent	360,0	4,8	102,0	220	-	13.1 x 57.2	1000	o. r.	o. r.	o. r.
91111	TY 46M	transparent	184,0	4,8	45,0	220	-	13.1 x 27	1000	o. r.	o. r.	o. r.
91112	TY 46MD	transparent	184,0	4,8	45,0	2 x 220	-	29.7 x 27	500	o. r.	o. r.	o. r.
91113	TY 46MT	transparent	184,0	4,8	45,0	3 x 220	-	46 x 27	500	o. r.	o. r.	o. r.
91114	TY 46MF	transparent	184,0	4,8	45,0	4 x 220	-	63.1 x 27	250	o. r.	o. r.	o. r.

### marking area above the latch

Part no. transparent	Type	Colour	Length mm	Width mm	Bundle Ø mm	Capacity N	Hole Ø mm	Field W x H	Unit	Net EUR/100 items at a purchase of		
										up to 1000	1001 - 5000	5001 - 10000
91106	TY 53M	transparent	102,0	2,4	16,0	80	-	20.6 x 9.3	500	o. r.	o. r.	o. r.
91107	TY 532M	transparent	212,0	2,4	51,0	80	-	20.6 x 9.3	1000	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request