


TY-RAP® special cable tie cable tie with steel lug lock

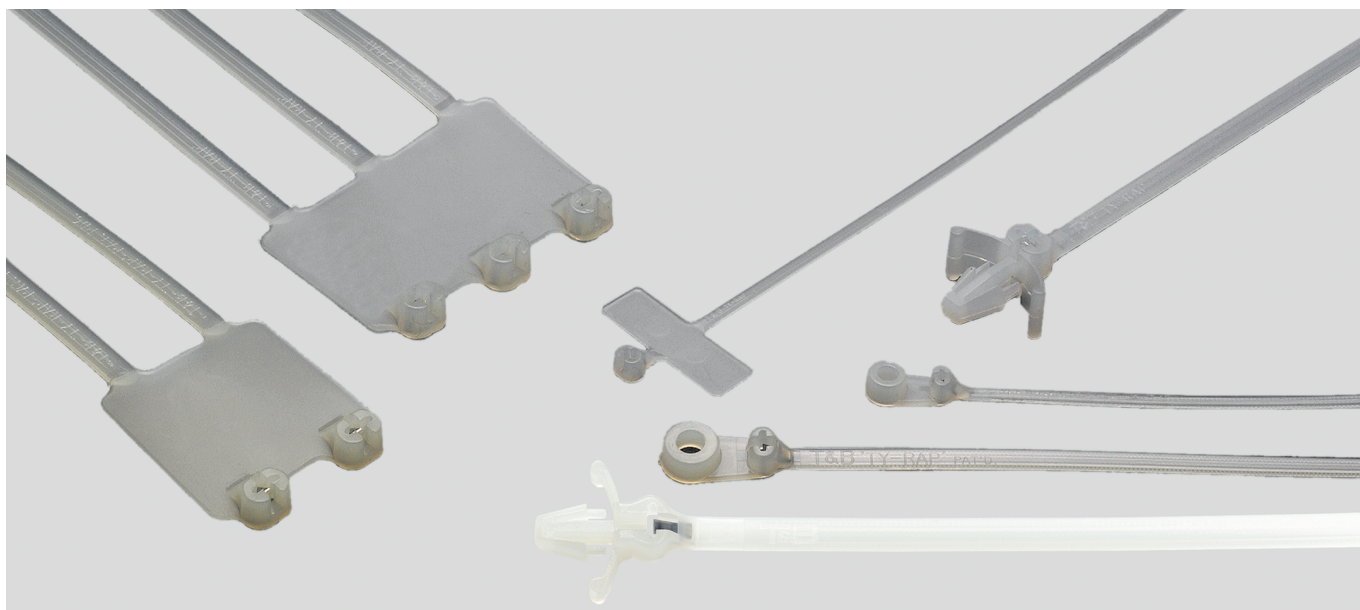

TY-RAP® (special types)

Cable tie with steel lug lock made of corrosion-resistant, non-magnetic steel. This technology enables the cable tie to offer excellent binding properties even under the most rigorous conditions such as heat, cold, humidity etc. and makes it insensitive to vibrations and external influences.

Material

Polyamide 6.6

- halogen-free
- silicone-free

Technical data

Temperature range: -60°C up to +85°C

Flammability acc. to UL 94: V2

with assembly hole

Part no.	Type	Colour	Length mm	Width mm	Bundle Ø mm	Capacity N	Hole Ø mm	Field W x H	Unit	Net EUR/100 items at a purchase of		
transparent										up to 1000	1001 - 5000	5001 - 10000
91093	TY 33M	transparent	102,0	2,3	16,0	80	3	-	1000	o. r.	o. r.	o. r.
91094	TY 34M	transparent	151,0	3,5	29,0	180	4,4	-	1000	o. r.	o. r.	o. r.
91095	TY 635M	transparent	198,0	4,7	45,0	220	4	-	1000	o. r.	o. r.	o. r.
91096	TY 35M	transparent	199,0	4,7	45,0	220	5,1	-	1000	o. r.	o. r.	o. r.
91098	TY 37M	transparent	356,0	7,7	90,0	540	6,7	-	500	o. r.	o. r.	o. r.

with plug-in clip

Part no.	Type	Colour	Length mm	Width mm	Bundle Ø mm	Capacity N	Hole Ø mm	Field W x H	Unit	Net EUR/100 items at a purchase of		
transparent										up to 1000	1001 - 5000	5001 - 10000
91103	TY 38M	transparent	200,0	4,7	44,0	220	-	-	1000	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request