


T-SK/SKU cable tie with steel lug lock

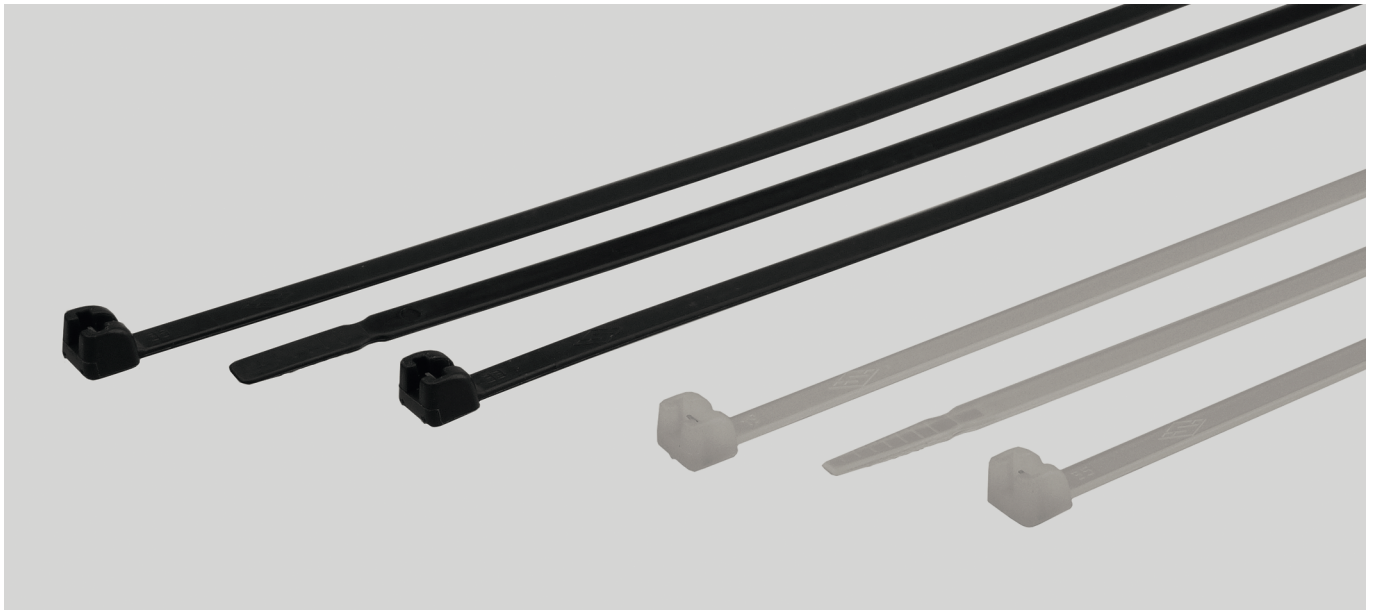

T-SK/SKU

Cable tie with steel lug made of corrosion resistant, non-magnetic steel for bundling and mounting cables and lines etc.

Material

Polyamide 6.6

- halogen-free
- silicone-free
- self-extinguishing

Technical data

Temperature range: -40°C up to +85°C

Flammability acc. to UL 94: V2

Properties

- high requirements to flexibility and resistance, also at low temperatures and dry climate
- high tension due to extra wide steel lugs

T-SK

Part no.	Type	Length mm	Width mm	Bundle Ø mm	Capacity N	Unit	Net EUR/ 100 items at a purchase of		
							up to 100	101 - 500	501 - 1000
907016	T-SK 2-24	100	2,5	24	180	1000	o. r.	o. r.	o. r.
907017	T-SK 2-55	200	2,5	55	180	1000	o. r.	o. r.	o. r.
907018	T-SK 3-36	140	3,5	36	280	1000	o. r.	o. r.	o. r.
907019	T-SK 3-55	200	3,5	55	280	1000	o. r.	o. r.	o. r.
907020	T-SK 3-80	280	3,5	80	280	1000	o. r.	o. r.	o. r.
907021	T-SK 4-51	186	4,5	51	400	1000	o. r.	o. r.	o. r.
907022	T-SK 4-76	290	4,5	76	400	1000	o. r.	o. r.	o. r.
907023	T-SK 4-101	360	4,5	101	400	1000	o. r.	o. r.	o. r.
907037	T-SK 7-95	340	7,0	95	700	500	o. r.	o. r.	o. r.

T-SKU UV-stabilized

Part no.	Type	Length mm	Width mm	Bundle Ø mm	Capacity N	Unit	Net EUR/ 100 items at a purchase of		
							up to 100	101 - 500	501 - 1000
907024	T-SKU 2-24	100	2,5	24	180	1000	o. r.	o. r.	o. r.
907025	T-SKU 2-55	200	2,5	55	180	1000	o. r.	o. r.	o. r.
907026	T-SKU 3-36	140	3,5	36	280	1000	o. r.	o. r.	o. r.
907027	T-SKU 3-55	200	3,5	55	280	1000	o. r.	o. r.	o. r.
907028	T-SKU 3-80	280	3,5	80	280	1000	o. r.	o. r.	o. r.
907029	T-SKU 4-51	186	4,5	51	400	1000	o. r.	o. r.	o. r.
907030	T-SKU 4-76	290	4,5	76	400	1000	o. r.	o. r.	o. r.
907031	T-SKU 4-101	360	4,5	101	400	1000	o. r.	o. r.	o. r.
907038	T-SKU 7-95	340	7,0	95	700	500	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request