

# Carbon composition film preset potentiometers




Series 6

Type VA 06 / SM063

Ordering code no.: 00 006 .....

Basic design: laminate base, plastic encased

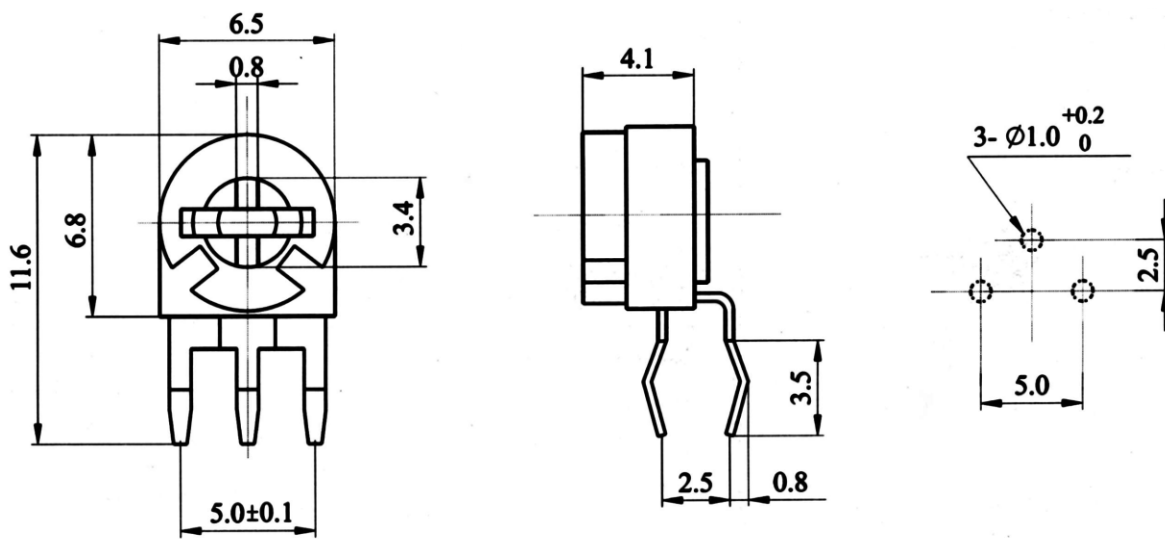

## Technical data

|                        |                             |                          |                          |
|------------------------|-----------------------------|--------------------------|--------------------------|
| Rated resistance range | 200 $\Omega$ - 1 M $\Omega$ | Limiting element voltage | 50 V                     |
| Resistance tolerance   | $\pm 30 \%$                 | Mechanical travel        | $210^\circ \pm 10^\circ$ |
| Law (resistance taper) | lin                         | Operating torque         | 0.5 - 3.5 Ncm            |
| Rated dissipation      | 0.1 W / 50 $^\circ\text{C}$ | End stop torque          | 3.5 Ncm                  |
| Durability             | 100 cycles                  |                          |                          |