

Laserliner


X1-Laser



360° line laser with hand-held receiver mode and magnetic clamp and wall bracket for varied applications

With the horizontal 360° laser line and the vertical laser line, objects in the entire room can be accurately aligned. Green laser technology guarantees optimum visibility. With the CrossGrip magnetic clamp and wall bracket, the device can be used as a standalone unit and, in a combination, horizontally as well as vertically. Thanks to the integrated handheld receiver mode, the X1 laser can also be used outdoors.

- Exact horizontal alignment of objects in the whole room
- Good visibility through green laser technology
- Time-saving automatic alignment
- Easy alignment of slopes
- Integrated hand-held receiver mode for outdoor applications
- Individually switchable laser lines
- Second battery for long operating time
- CrossGrip clamp and wall bracket

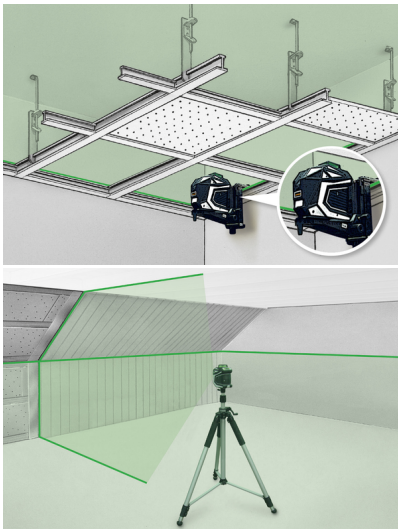

TECHNICAL SPECIFICATIONS

SELF-LEVELLING RANGE	± 3°
ACCURACY	± 0.2 mm / m
LEVELLING	automatic
VISIBILITY (TYPICAL)*	60 m
WORKING RANGE WITH HAND RECEIVER	(depends on how the technology affects the difference in brightness) 60 m
LASER WAVELENGTH	515 nm
LASER CLASS	2 / < 1 mW (EN 60825-1:2014/AC:2017)
POWER SOURCE	Li-ion battery pack 3.7V / 5.2Ah Power adapter 5VDC / 2A
OPERATING TIME	approx. 15 hours
OPERATING CONDITIONS	0°C ... 50°C, max. humidity 80% rH, no condensation, max. working altitude 4000 m above sea level
STORAGE CONDITIONS	-10°C ... 70°C, max. humidity 80% rH
DIMENSIONS (W X H X D)	122 mm x 121 mm x 75 mm
WEIGHT	638 g (incl. battery pack)
	* at max. 300 lux

Optional: RangeXtender G 60
Artikel-Nr. 033.55A



X1-Laser	ORDER NO. 031.500A	EAN-CODE 4021563709663	PU 1
----------	--------------------	------------------------	------