

Imou



Cruiser 2

Full  Color

5MP Outdoor Wi-Fi P&T Camera

Cruiser delivers 5MP live monitoring with a choice of 3.6mm lens option, With 5MP 3K live monitoring and 0~340° pan & 0~90° tilt features, Cruiser 2 5MP ensures every corner of your home completely covered. It supports four night vision modes for clear-as day clarity even in pitch dark. With IP66 certified, the camera can be used outdoors under different weather conditions. With built-in spotlight and security siren, Cruiser 2 5MP actively keeps unwelcome visitors away from what you care about.



5MP 3K Video
See more than 3MP



AI Human & Vehicle Detection
Quickly find human/vehicle targets



Smart Color Night Vision
Support four-mode night vision for clear-as day clarity even in pitch dark



Active Deterrence
Scare away unwelcome visitors with built-in spotlight and 110dB security siren



IP66
Weatherproof from dust and water



Two-way Talk
Real-time communicate with people at the camera



Diversified Storage
Supports NVR, Cloud Storage or Micro SD card (up to 256GB)




Alarm Notification
Sends instant motion-activated alerts to your mobile phone



Wi-Fi Connection
IEEE802.11 ax/b/g/n(2.4GHz)



Smart Tracking
Automatically tracks moving objects

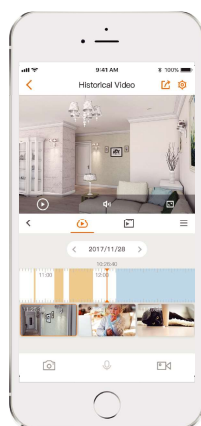

Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and play back anytime anywhere.

<http://www.imoulife.com>

Specifications

Camera

1/2.7" 5 Megapixel Progressive CMOS
5MP (2880 x 1620)
Night Vision: 30m(98ft) Distance
3.6mm Fixed Lens
Field of View: 85° (H), 42° (V), 102° (D)
0~340° Pan & 0~90° Tilt

Video & Audio

Video Compression : H.265/H.264
Up to 25/30 fps Frame Rate
8x Digital Zoom
Built-in Mic & Speaker, 110dB Siren
Two-way Audio

Notice Management

Motion Detection
Configurable Region
Human Detection
Vehicle Detection

Network

1 x 100Mbps Ethernet Port
Wi-Fi 6:IEEE802.11 ax/b/g/n, Dual Antenna 120m Open Field
Imou App: iOS, Android
ONVIF

Auxiliary Interface

Micro SD Card Slot (up to 256GB)
Built-in Mic & Speaker
Reset Button

General

DC 12V1A Power Supply
Power Consumption:<12 W
Material: Plastic
Working Environment: -30° C~+60° C, Less Than 95%RH
Dimensions: 110.4 × 128.8 × 132.7mm (4.33 × 5.07 × 5.22 inch)
Weight: 423g (0.93lb)
CE, UKCA
IP66

What's in the box

- 1x Camera
- 1x Quick Start Guide
- 1x Power Adapter
- 1x Mounting Template
- 1x Waterproof Connector
- 1x Screw and Anchor pack

