



Imou

Cell Go


IPC-B32P-V2
IPC-B32N-V2

With Magnetic Accessory

3MP H.265 Wi-Fi Battery Camera


The Cell Go is a 100% wire-free rechargeable camera that delivers well-rounded home protection for up to 120 days on one single charge. 2K , IP65 Weatherproof , Night Vision , Compatible with Amazon Alexa, No monthly fee. Easy wireless installation—no need to connect your security camera to electrical wiring.

- 3MP QHD Video**
See more details than 1080P
- 100% Wire-Free**
Supports 2.4 GHz Wi-Fi, Free of network cabling and power wiring hassles
- Rechargeable Battery**
DC 5V Power Supply Rechargeable Battery Power
- Built-in Siren**
Scare away unwelcome visitors with built-in siren
- PIR Detection**
High quality passive PIR detector for reducing false alerts
- Low-Battery Notifications**
Informs you when battery level goes down to 20%,10%, so you can charge it in time.
- Two-way Talk**
Using variable sound when taking real-time talk with people in front of the camera
- Human Detection**
Quickly find human targets in your home
- Privacy Mode**
Device goes to sleep to protect your personal privacy
- IP65**
Weatherproof for outdoor conditions
- Internal Storage**
Built-in 4 GB eMMC Storage
- Works with Solar Panel**
Works with Imou Solar Panel for battery charging

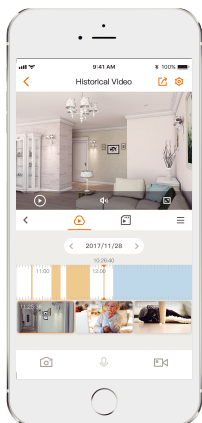

Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and playback anytime anywhere.

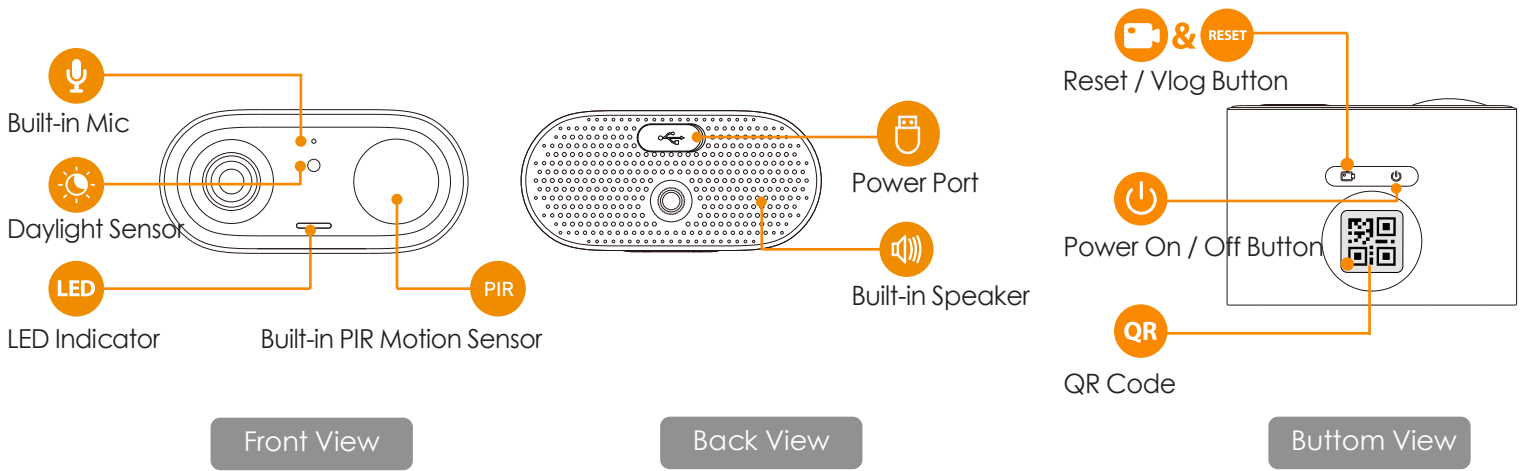

Specifications

Camera

3MP(2304*1296)
 Night Vision: 7m(23ft) Distance
 2.8mm Fixed Lens
 Field of View : 98° (H), 54° (V), 121° (D)

Video & Audio

Video Compression : H.265
 Up to 15fps Frame Rate
 8x Digital Zoom
 Two-way Audio

Notice Management

Motion Detection
 Human Detection
 Configurable Region
 Work mode

Storage

Local Storage: Internal Storage(4GB eMMC)
 Secure Local Storage. No monthly fee.
 Cloud Storage: Imou Subscription Plan
 Record, view, and save events in your Imou app with a 365 day trial of the Imou Subscription Plan.

Network

Wi-Fi:IEEE802.11b/g/n,50m Open Field
 Imou App: iOS, Android

Auxiliary Interface

Built-in Mic & Speaker
 Power on / off Button
 Vlog / Reset Button

General

DC 5V 2A Power / Imou Solar Panel Supply
 Power Consumption:<3.5W
 Operating Temperature:-20°C~+50°C (-4°F~122°F)
 Charging Temperature:-0°C~+45°C (32°F~112°F)

Device Dimensions: 88×60×42mm (3.46×2.36×1.65 inch)
 Dimensions(With package): 123×57×147mm (4.84×2.24×5.78 inch)
 Device Weight: 208.9g (0.46lb)
 Weight(With package): 415.3g(0.92lb)

FCC,CE,IC ID,UKCA,RCM,WWA

What's in the box

- 1x Camera
- 1x Quick Start Guide
- 1x Power Cable
- 1x Mounting Template
- 1x Tape
- 1x Mounting Bracket
- 3x Expansion Screw
- 1x Magnetic Accessory

