

SPECIFICATION:

Current rating: 1 A
 Voltage rating: 100 V
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 800 V AC
 Wire range: AWG24-30
 Insulation outer diameter: 1.4 mm max.
 Operation temperature: -25 °C to +85 °C

RoHS
COMPLIANT



MATERIAL:

Contact: Phosphorbronze

FINISH:


Contact: Tin plated

HANDLING:




Packing: Reel with 10K, otherwise separately cut

TOLERANCE:

.X ± 0.20
 .XX ± 0.10

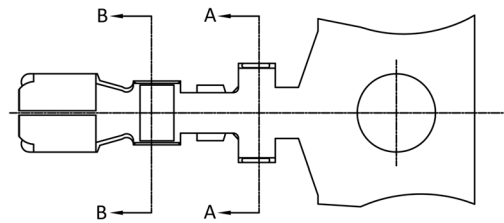

SEC: A-A

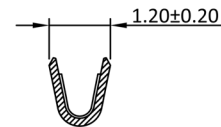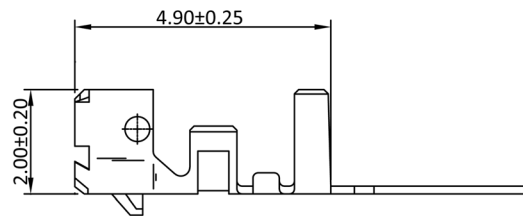 

SEC: B-B

Order-Information

Identifier:

CR22K

Terminal for H22H-Series

Packing unit:

#

empty: separately, cut

10: Reel with 10.000 pcs.