

Board-to-Wire Connectors Pitch 2.5 mm Floppy

Male Housing 4 pole and Contacts



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 3 A
 Voltage rating: 250 V
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 800 V AC
 Operation temperature: -25 °C to +85 °C
 Wire range: AWG20-24
 Insulation outer diameter: 1.8 mm

MATERIAL:


 
 
 




Housing: Nylon 66 white UL94V-0
 Contact: Brass

FINISH:

Contact: Tin plated

TOLERANCE:

.X ± 0.30
 .XX ± 0.25

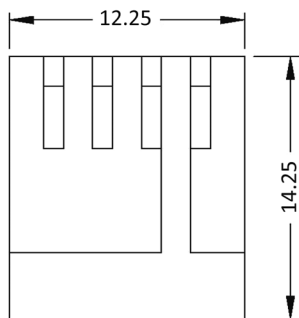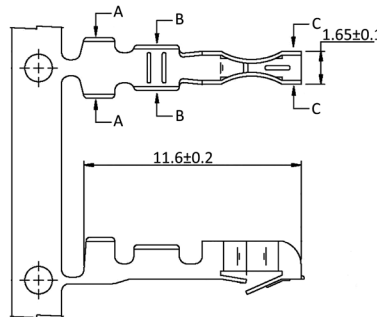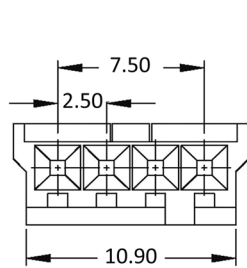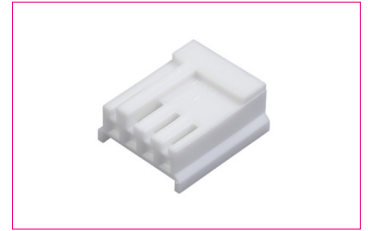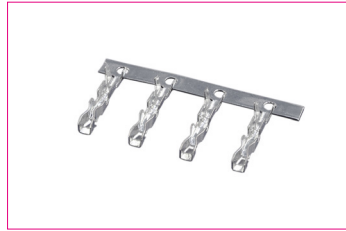

Order-Information

Identifier:

FS03

Floppy power plug

Version:

#

empty: housing with four contacts

G: only housing

CR: only contact (100 pcs cut)

CR10K: only contact (roll with 10.000 pcs.)