

FireWire Connectors Plugs

Cable Plug 6 pin, Solder Termination



SPECIFICATION:

Operating Current (Nom.):	1 A
Operating Temperature:	-40°C to 70°C
Insulation Resistance (Min.):	100 MΩ
Contact Resistance (Max.):	30 mΩ
Dielectric Strength:	500 Vac
Insertion Force (Max.):	15 N
Extraction Force:	9,8 N

MATERIAL:




Material (Terminal):	brass, tin plated
Material (Housing):	steel, nickel plated
Flammability Class:	UL 94 V-0
Material (Insulation):	PBT
Material (Contact Area):	brass, gold plated

HANDLING:

Packaging:	bulk
------------	------

TOLERANCE:

.X:	± 0.20
.XX:	± 0.10

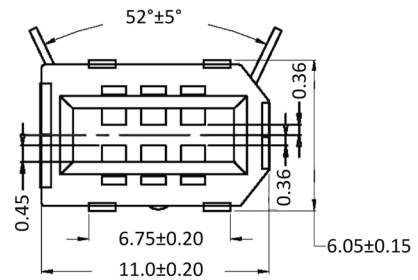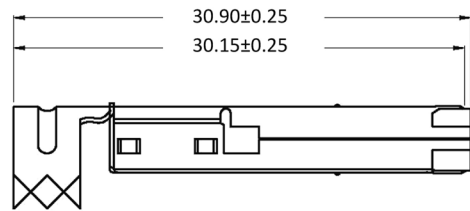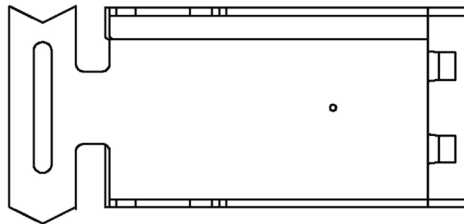

Order Information

Identifier:

FWS6L

Cable plug solder termination