
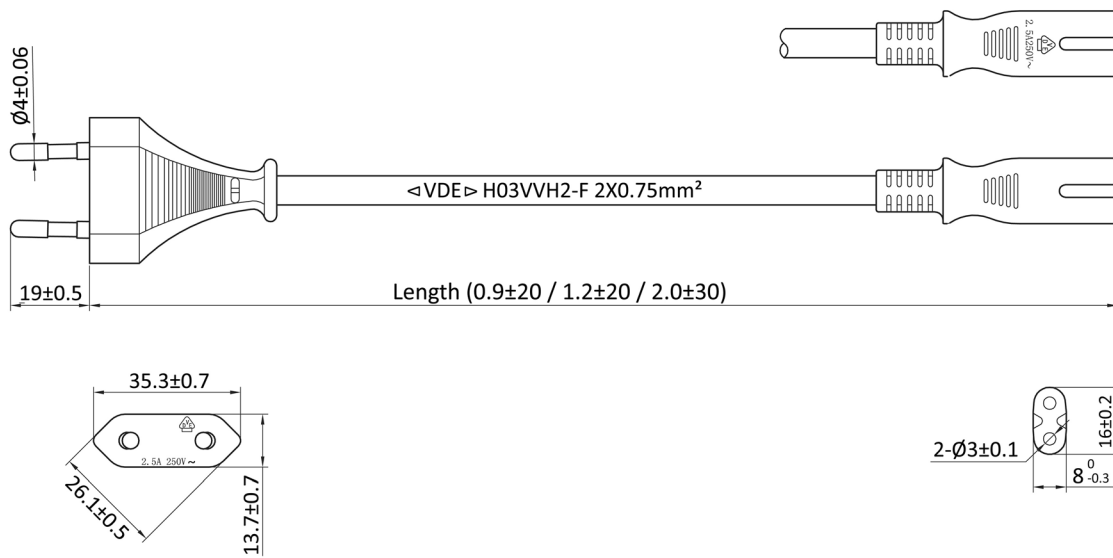


**SPECIFICATION:**

Operating Voltage (Nom.):	250 Vac
Current Leakage:	1 mA
Insulation Resistance (Min.):	5 MΩ
Dielectric Strength:	2,500 Vac
Diameter:	3.5 mm x 5.7 mm
Strands Cross Section:	0.75 mm <sup>2</sup>
Strands Layout:	42 x 0.148 mm
Core Diameter:	2.2 mm

**MATERIAL:**

Type: H03-VVH2-F

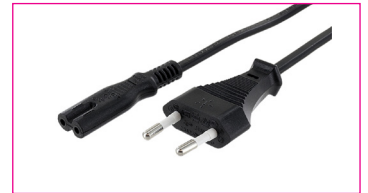

**Order Information**

Identifier:	Colour:	Length:
<b>NK8</b>	<b>SW</b>	<b>#</b>
Power cable with 8-form female	black	<b>0,9:</b> 0.9 m
		<b>1,2:</b> 1.2 m
		<b>2:</b> 2.0 m