

**Stranded Copper Jumper Wire**  
Copper insulated

1-wire, 0.04 mm<sup>2</sup>, 10 m



**SPECIFICATION:**


Operating Voltage (Nom.): 100 V  
 Operating Temperature: -5°C to 85°C  
 Strands Cross Section: 0.04 mm<sup>2</sup>  
 Diameter: 0.6 mm

**MATERIAL:**

Material (Insulation): PVC

**HANDLING:**

Packaging: ring

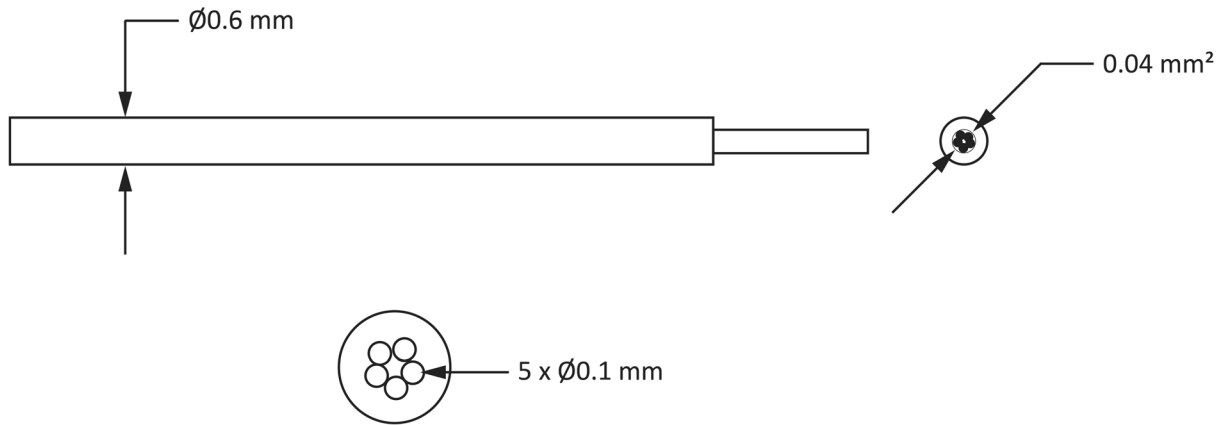

**Order Information**

Identifier:	Version:	Colour:	Length:
KL	004	#	10
Stranded copper wire	0.04 mm <sup>2</sup>	SW: black	10 m
		RT: red	
		BL: blue	
		GE: yellow	
		GN: green	
		BR: brown	
		GR: grey	
		OR: orange	
		VIO: violett	
		WS: white	