

Stranded Copper Jumper Wire Copper insulated

1-wire, 0.14 mm², 100 m



SPECIFICATION:


Operating Voltage (Nom.): 500 V
Operating Temperature: -5°C to 85°C
Strands Cross Section: 0.14 mm²
Diameter: 1.3 mm

MATERIAL:

Material (Insulation): PVC

HANDLING:

Packaging: reel

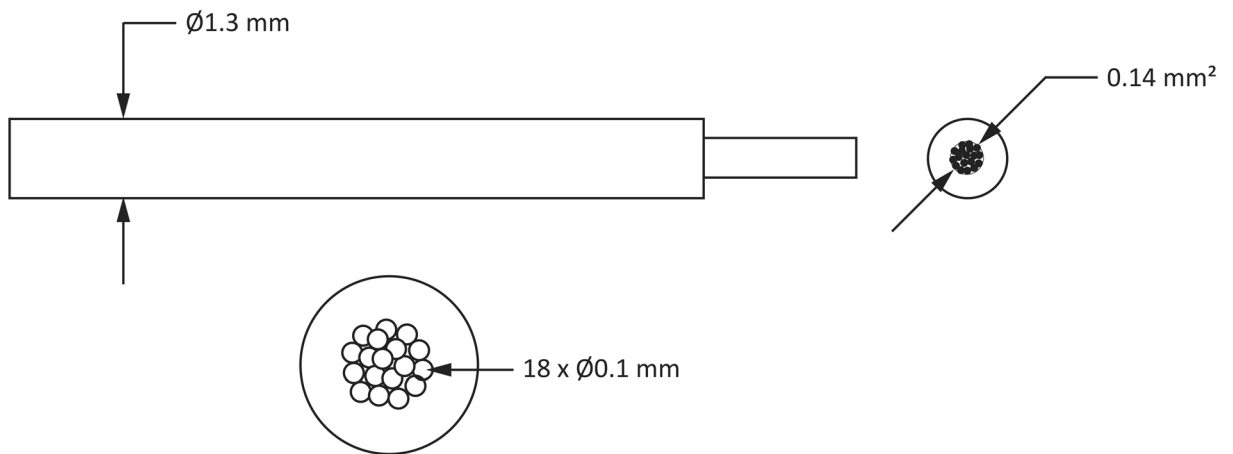

Order Information

Identifier:	Version:	Colour:	Length:
KL	014	#	100
Stranded copper wire	0.14 mm ²	SW: black RT: red BL: blue GE: yellow GN: green BR: brown GR: grey OR: orange VIO: violett WS: white	100 m