

Stranded Copper Jumper Wire Copper insulated

1-wire, 0.14 mm², 10 m



SPECIFICATION:


Operating Voltage (Nom.): 500 V
Operating Temperature: -5°C to 85°C
Strands Cross Section: 0.14 mm²
Diameter: 1.3 mm

MATERIAL:

Material (Insulation): PVC

HANDLING:

Packaging: ring

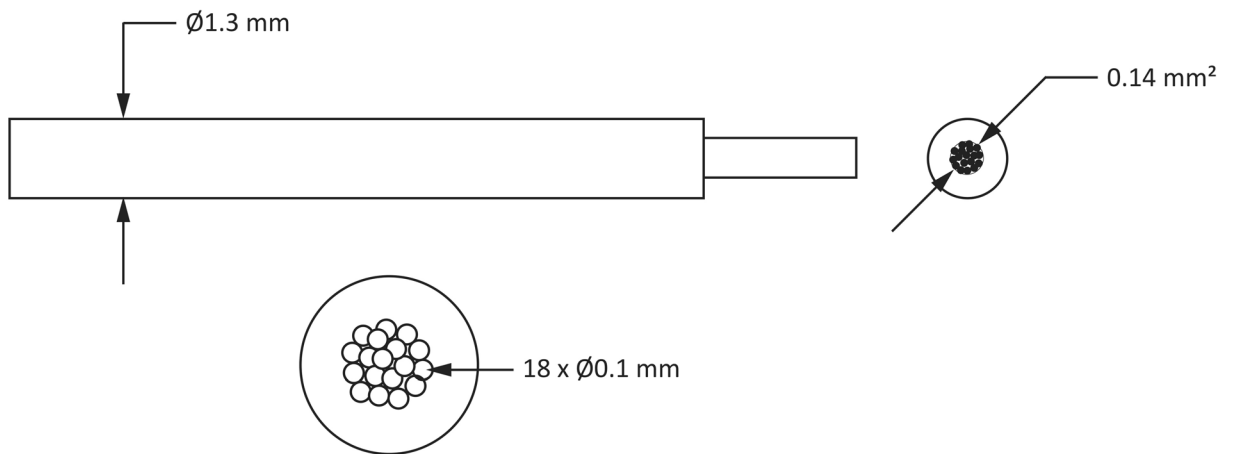

Order Information

Identifier:	Version:	Colour:	Length:
KL	014	#	10
Stranded copper wire	0.14 mm ²	SW: black	10 m
		RT: red	
		BL: blue	
		GE: yellow	
		GN: green	
		BR: brown	
		GR: grey	
		OR: orange	
		WS: white	