

# Stranded Copper Jumper Wire Copper insulated

1-wire, 0.25 mm<sup>2</sup>, 50 m



### SPECIFICATION:


Operating Voltage (Nom.): 500 V  
Operating Temperature: -5°C to 85°C  
Strands Cross Section: 0.25 mm<sup>2</sup>  
Diameter: 1.3 mm

### MATERIAL:

Material (Insulation): PVC

### HANDLING:

Packaging: reel

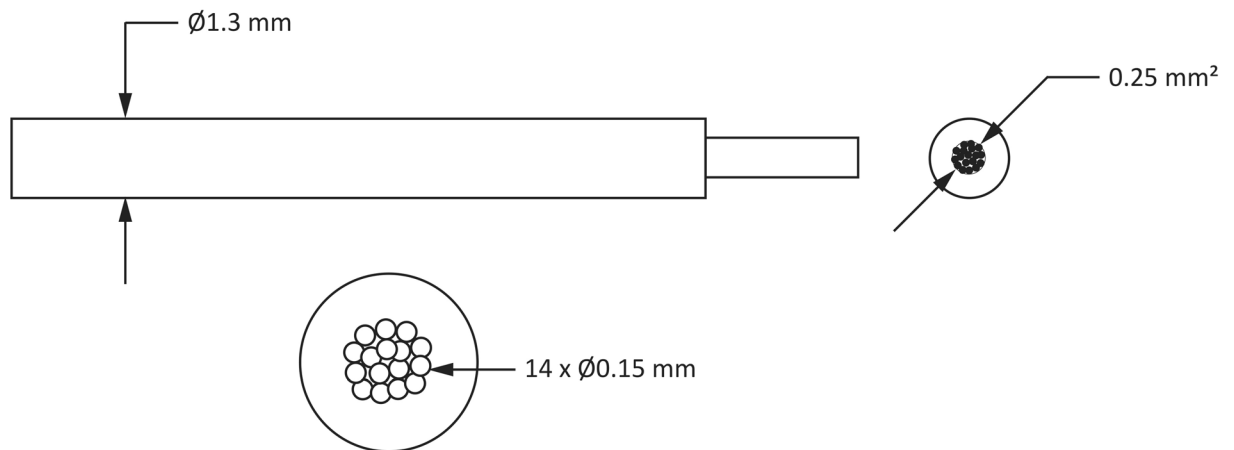

### Order Information

Identifier:	Version:	Colour:	Length:
KL	025	#	50
Stranded copper wire	0.25 mm <sup>2</sup>	SW: black BL: blue RT: red GE: yellow GN: green BR: brown GR: grey OR: orange VIO: violett WS: white	50 m