

SCRAPER SCRAPEX CLEANY

ORDER NOW!

Order No.	5644.08
Knife size (L x W x H)	105.5 x 11.5 x 50 mm
Weight knife	35.0 g
Basic material	Plastic
Variations	544.00



BLADE
RETRACTABLE

Easy blade change
for efficient working


3-in-1 slider
for releasing, concealing
and changing the blade

Practical eyelet
for a secure
attachment

Large scraping width (36 mm)
for cleaning surfaces

Rounded, retractable blade
to protect against damage
and injuries

Rounded ergonomic handle
for right and left handers

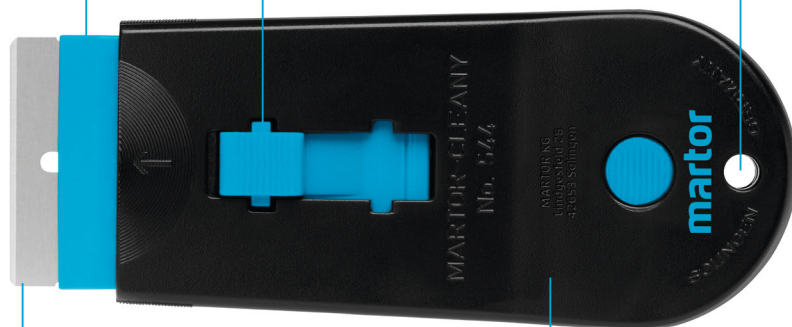


THE SAFER WAY TO CUT.

martor

MARTOR SCRAPER SCRAPEX CLEANY

SAFETY TECHNOLOGY

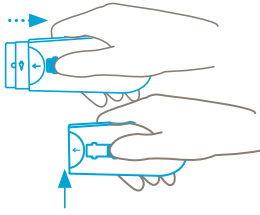

Blade retractable

The blade is permanently accessible. However, you can retract it manually into the handle when laying the knife down and transport it safely.

TECHNICAL FEATURES



Tool-less blade change



Ergonomic



Scraper width (36mm)



For right and left handers



Lanyard hole



Blade retractable



Rounded-tip industrial blade



Printable for promotional purposes

EXAMPLES OF USE



MAIN CUTTING MATERIALS



Self-adhesive label



Ceramic glass cooker top

MOUNTABLE BLADES



REINFORCED RAZOR BLADE NO. 60044 **NO. 60044.50**
0.30 mm, rounded blade tips,
10 in magazine



REINFORCED RAZOR BLADE NO. 44 **NO. 44.50**
0.30 mm, 10 in magazine



REINFORCED RAZOR BLADE NO. 144 **NO. 144.50**
0.25 mm, stainless, 10 in magazine

PACKING INFORMATION

Packaging unit	1 scraper (loose) (10 in box (loose) in multipack)
Weight scraper	35.0 g
EAN Code scraper	4002632803949
Size outer pack	105 x 105 x 60 mm
Weight outer pack	388.5 g
EAN Code outer pack	4002632853944